

顶丝式固定环

标准型




■标准型



类型	M 材质	S 表面处理	A 附件
SCBBA	一般结构用钢	四氧化三铁保护膜	2个止动螺丝
SCBEA		无电解镀锌	
SCBNA	不锈钢	-	2个止动螺丝(不锈钢)
SCBCA	铝合金	本色阳极氧化	

A3
固定环

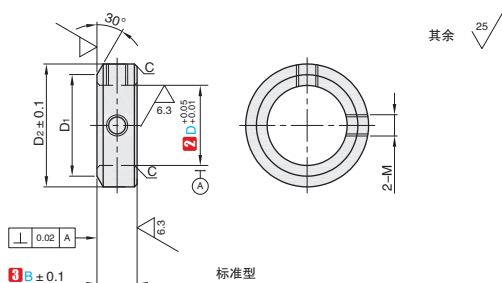

订购编号示例

①代号 - ②D - ③B
SCBBA - D10 - B8

①代号	内径		主要尺寸			
	②D	③B	D ₁	D ₂	M×I	C
SCBBA SCBEA SCBNA SCBCA	3	6 8	4.5	7	M3×3	0.2
	4	6 8	5.5	8	M3×3	
	5	6 8 10	10	11	M4×3	
	6	6 8 10	11	12	M4×3	
	8	6 8 10	12	14	M4×3	
	10	6 8 10	13	16	M4×3	0.5
	12	6 8 10 12	15	20	M5×4 (仅B6为M5×3)	
	13	8 10 12	18	22		
	15	8 10 12	20	24	M6×5 (仅B8为M5×4)	
	16	8 10 12 15	22	26		
18	10 12 15	27	32			
20	10 12 15	27	32	M8×6	1	
25	12 15 18	31	38			
30	15 18 20	38	46			
35	15 18 20	40	50			
40	20 22	45	60			M10×8
50	20 22 25	55	70			