

精致型梯形齿橡胶带

T10 型



■ T10 型

进口产品

CAD 2D/3D




标准加工袋

型式	齿面保护层	材质	芯线
HQ-ABRN-T10	尼龙帆布	氯丁橡胶	玻璃纤维

产品特点: 用于通讯食品机械、医疗机械、钢铁机械、石油化工、仪器仪表、各种精密机床等。

▲注: 使用温度 -20~80℃。

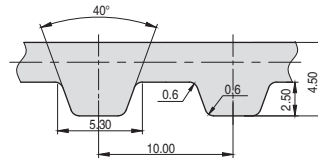

HQ-ABRN-T10
T10 型

订购编号示例

① 代号	② 齿形	③ 公称宽度	④ 编号
HQ-ABRN	-	T10250	- 400

HQ-ABRN-T10 (齿距: 10mm)					
① 代号	② 齿形	③ 公称宽度	④ 编号	周长 (mm)	齿数
HQ-ABRN	T10	100 (10mm)	260	260	26
			340	340	34
			350	350	35
			360	360	36
			370	370	37
			380	380	38
			400	400	40
			410	410	41
			440	440	44
			460	460	46
		150 (15mm)	480	480	48
			500	500	50
			530	530	53
			550	550	55
			560	560	56
			570	570	57
			580	580	58
			600	600	60
			610	610	61
			630	630	63
		200 (20mm)	650	650	65
			660	660	66
			690	690	69
			700	700	70
			720	720	72
			730	730	73
			740	740	74
			750	750	75
			770	770	77
			790	790	79
		250 (25mm)	800	800	80
			810	810	81
			840	840	84
			850	850	85
			870	870	87
			880	880	88
			890	890	89
			900	900	90
			920	920	92
			950	950	95
300 (30mm)	960	960	96		
	980	980	98		
	1000	1000	100		

HQ-ABRN-T10 (齿距: 10mm)					
① 代号	② 齿形	③ 公称宽度	④ 编号	周长 (mm)	齿数
HQ-ABRN	T10	100 (10mm)	1010	1010	101
			1040	1040	104
			1050	1050	105
			1080	1080	108
			1100	1100	110
			1110	1110	111
			1140	1140	114
			1150	1150	115
			1200	1200	120
			1210	1210	121
		150 (15mm)	1240	1240	124
			1250	1250	125
			1280	1280	128
			1300	1300	130
			1320	1320	132
			1350	1350	135
			1390	1390	139
			1400	1400	140
			1420	1420	142
			1450	1450	145
		200 (20mm)	1460	1460	146
			1500	1500	150
			1560	1560	156
			1600	1600	160
			1610	1610	161
			1630	1630	163
			1640	1640	164
			1690	1690	169
			1700	1700	170
			1720	1720	172
		250 (25mm)	1750	1750	175
			1800	1800	180
			1860	1860	186
			1880	1880	188
			1960	1960	196
			2020	2020	202
			2100	2100	210
			2250	2250	225
			2500	2500	250
			3000	3000	300
300 (30mm)	3600	3600	360		