



★ 产品特点: 每一个脚能经受反复多次的弯曲, 并且在弯曲部分不发生断裂或裂缝。符合GB/T 91-2000。


■ 开口销

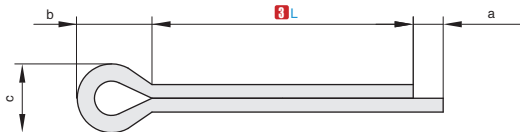

③代号 STB	☒材质 SUS304
------------	---------------

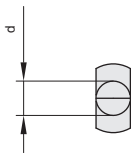

 (平头)



视角标准: 第一视角



订购编号示例

①代号	-	②D	-	③L
STB	-	D2	-	L12

①代号	②D适用孔径	③L			a(约)	b	c	d			
STB	0.8	8	10	12	1.6	2.4	1.4	0.7			
	1		10	12	15	1.6	3	1.8	0.9		
	1.2		10	12	15	2.5	3	2	1		
	1.6		10	12	15	2.5	3.2	2.8	1.4		
	2			12	15	2.5	4	3.6	1.8		
	2.5				15	20	2.5	5	4.6	2.3	
	3.2					20	3.2	6.4	5.8	2.9	
	4					20	25	4	8	7.4	3.7
	5						35	4	10	9.2	4.6