


重载型支脚

 
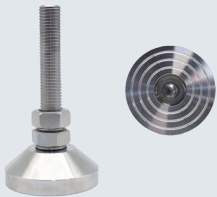


★ 产品特点: 内置轴承, 调平操作方便。

■ 固定调节型·带轴承型



① 代号	底盘		螺杆	
	M 材质	M 材质	S 表面处理	
SFDSML	SUS304	SUS304	无	

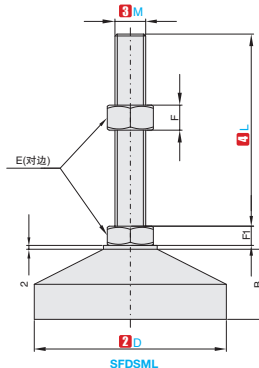

① 代号 - ② 底径 - ③ 螺纹直径 - ④ 螺纹长度
SFDSML - D100 - M16 - L100

型号		主要尺寸							承载(kg)	参考重量(kg/pcs)
① 代号	② D	③ M	④ L	E	B	F	F ₁			
不锈钢 SFDSML	100	M16	100	24		13	10	1500	0.44	
			125						0.48	
			150						0.56	
		M20	100	30	36.5	16	13		2000	0.46
			125							0.50
			150							0.54
	M24	100	36		19		3500	0.51		
		125						0.59		
		150						0.65		
			200							0.75

▲ 承载与参考重量仅供参考。