

# ISV distribution enclosures

## Accessories

### Cross rails

#### for TS, SE

For horizontal sub-division of the support frame in the TS/SE enclosure.

#### Material:

– Sheet steel

#### Surface finish:

– Zinc-plated

Width unit		Packs of	Model No.
WU	mm		
2	500	2 pc(s).	<b>9666.722</b>
3	750	2 pc(s).	<b>9666.723</b>
4	1000	2 pc(s).	<b>9666.724</b>

1 WU  $\triangleq$  250 mm



### Mounting angles

#### for TS, SE

For vertical sub-division of the support frame in the TS/SE enclosure.

#### Material:

– Sheet steel

#### Surface finish:

– Zinc-plated

Height unit		Packs of	Model No.
U	mm		
2	300	2 pc(s).	<b>9666.702</b>
3	450	2 pc(s).	<b>9666.703</b>
4	600	2 pc(s).	<b>9666.704</b>
5	750	2 pc(s).	<b>9666.705</b>
6	900	2 pc(s).	<b>9666.706</b>
7	1050	2 pc(s).	<b>9666.707</b>
11	1650	2 pc(s).	<b>9666.711</b>
12	1800	2 pc(s).	<b>9666.712</b>

1 U  $\triangleq$  150 mm



#### Accessories:

– Equipment support connector, see page 305

### Mounting angles

#### for AE

For vertical sub-division of the support frame in the AE enclosure.

#### Material:

– Sheet steel

#### Surface finish:

– Zinc-plated

Height unit		Packs of	Model No.
U	mm		
3	450	2 pc(s).	<b>9666.753</b>
4	600	2 pc(s).	<b>9666.754</b>
6	900	2 pc(s).	<b>9666.756</b>
7	1050	2 pc(s).	<b>9666.757</b>

1 U  $\triangleq$  150 mm



### Depth stay

- For enclosure depth 400/500/600 mm
- For attaching the support frame in the TS/SE enclosure


#### Material:

– Sheet steel

#### Surface finish:

– Zinc-plated

Packs of	Model No.
2 pc(s).	<b>9666.730</b>

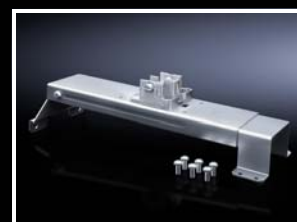

### Equipment support connector

- For connecting 2 mounting angles for TS/SE
- Increases the stability of the frame structure

#### Material:

– T-section: Aluminium

Packs of	Model No.
4 pc(s).	<b>9666.740</b>

