


Befestigungsart 05
 Mounting mode 05
 Mode de fixation 05

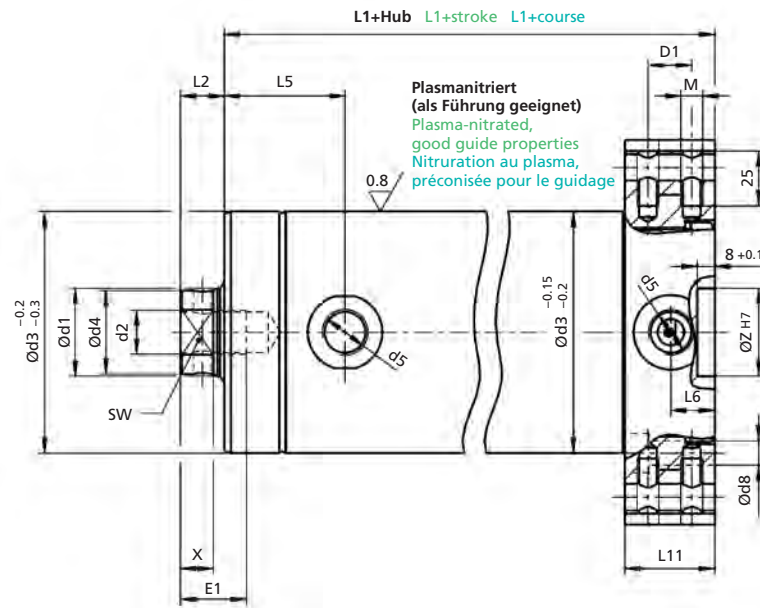

Bestellbezeichnung (Beispiel)
 Order specification (example)
 Référence de commande (exemple)

HZF 160 .80/50. 05. 204. 100




Kolben Ø Piston Ø Ø Piston	Stangen Ø Rod Ø Ø Tige	Befestigungsart Mounting mode Mode de fixation	Funktionsart Operation mode Mode de fonctionnement				Hub Stroke Course	Option Option Option	d2	d3	d4	d5	d8	L1				L2	L5	L6	L11	Z	D1
			□	□	□	□								201	204	206	208						
63	40	05	201	204	206	208	Kundenwunsch Requested by customer Demande du client	V	M20	110	38	G1/2"	11	209	271	254	226	20	55	20	41	40	20
80	50	05	201	204	206	208			M30	130	48	G3/4"	17,5	228	295	275	248	25	65	27	50	40	25
100	60	05	201	204	206	208			M36	155	58	G3/4"	22	242	335	312	265	30	80	27	55	40	25
125	80	05	201	204	206	208			M36	180	78	G3/4"	22	277	375	352	300	30	80	27	55	60	25
140	90	05	201	204	206	208			M36	195	88	G3/4"	26	287	385	362	310	35	80	27	55	60	25

Technische Änderungen vorbehalten
 Subject to change without notice
 Sous réserve de modifications

Maße in mm
 Dimensions in mm
 Dimensions en mm

Berechnungsgrundlage siehe ahp informiert
 Calculation based on „Information from AHP“
 Base de calcul, voir «AHP vous informe»

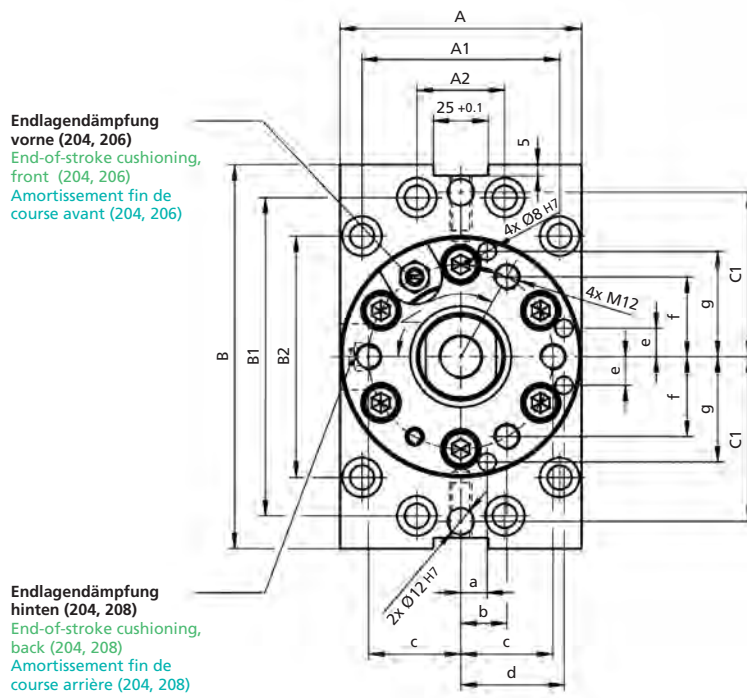

M	E1	A	A1	A2	B	B1	B2	C1	X	a	b	c	d	e	f	g	SW	∠
M10	30	110	90	40	175	145	110	75	15	12	21	42	47	13	36.4	48	32	60°
M12	35	130	102	60	185	155	122	80	18	19	30	50	56.5	14	45	55	41	60°
M12	40	155	118	64	225	190	150	95	18	22	31.2	62,8	68	15	54.1	65	50	60°
M12	40	180	140	65	250	210	170	105	18	30	45	75	77.5	20	60	75	-	60°
M12	55	195	152	85	260	220	180	115	18	52	60	80	86	15	55	70	-	45°