



产品特点：适用于中度负载结构：机器结构框架、物料车、工作台、工厂车间隔断展示架等。

技术信息

1 铝型材

2 紧固件

3 连接件



4 型材附件

5 地面组件



6 防护系列

7 门窗组件



8 精益管及配件

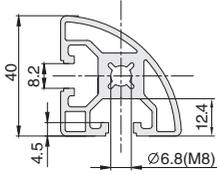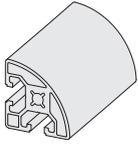



AE40-4040-2-R

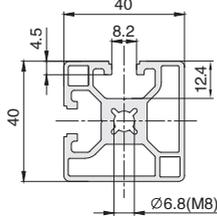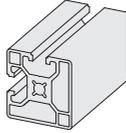



AE40-4040-2-N

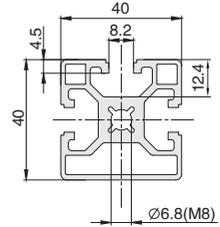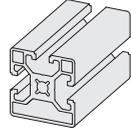



AE40-4040-3

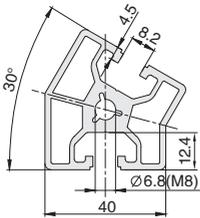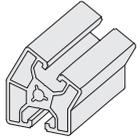



AE40-4430-2

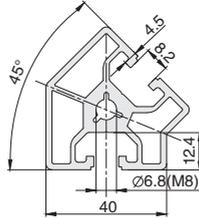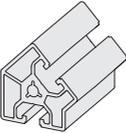



AE40-4445-2

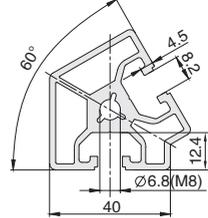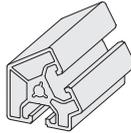



AE40-4460-2

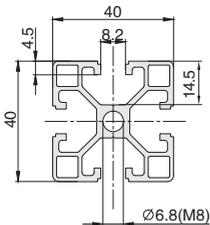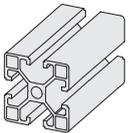



AE40-4040-4-SL

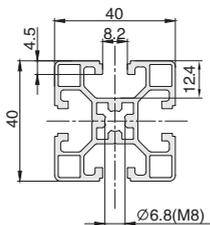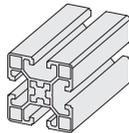

AE40-4040-4-L

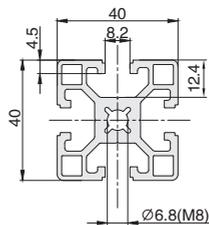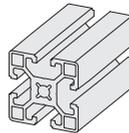



AE40-4040-4

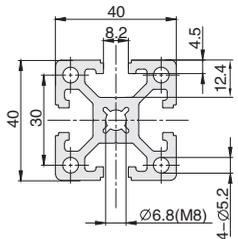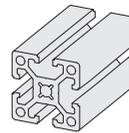



AE40-4040-4-H





■ 产品特点：适用于中度负载结构：机器结构框架、物料车、工作台、工厂车间隔断展示架等。

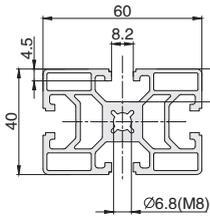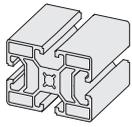



AE40-4060-4

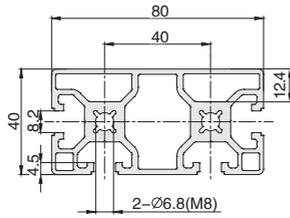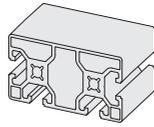



AE40-4080-4

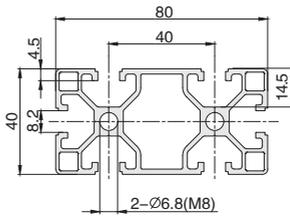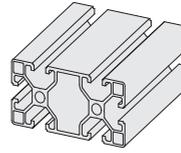



AE40-4080-6-SL

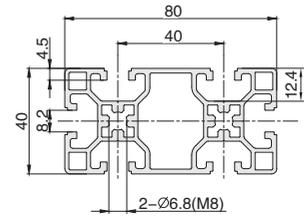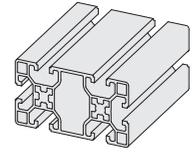



AE40-4080-6-L

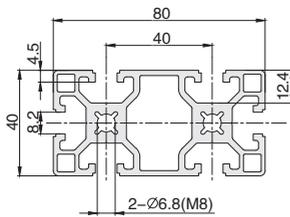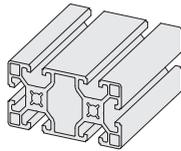



AE40-4080-6

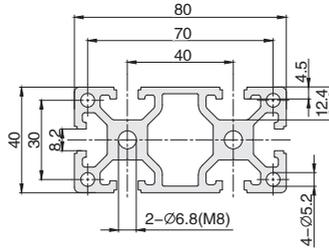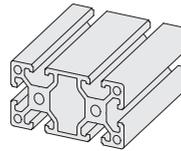



AE40-4080-6-H

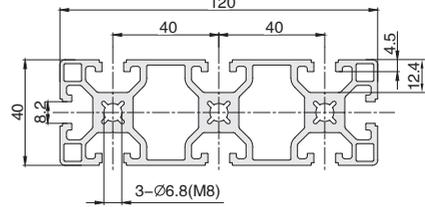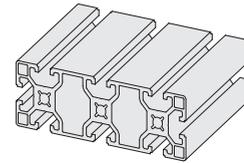

AE40-40120-8

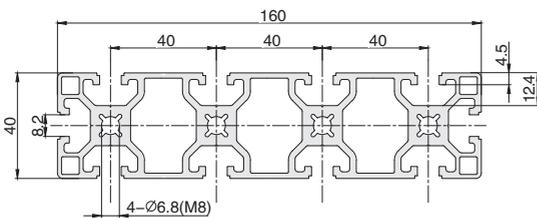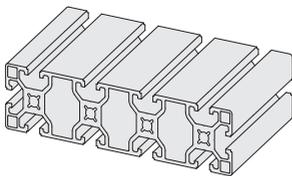

AE40-40160-10

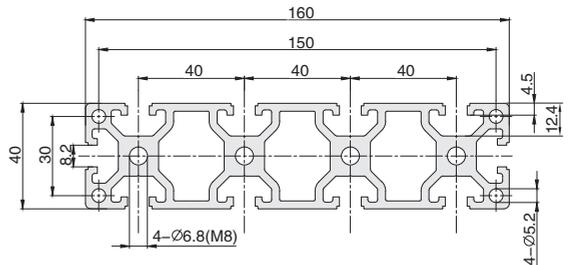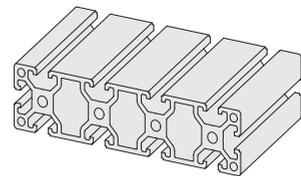

AE40-40160-10-H



产品特点：适用于中度负载结构：机器结构框架、物料车、工作台、工厂车间隔断展示架等。

技术信息

1 铝型材

2 紧固件

3 连接件



4 型材附件

5 地面组件



6 防护系列

7 门窗组件



8 精益管及附件

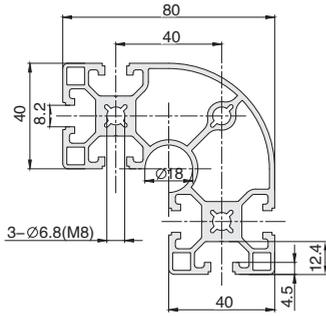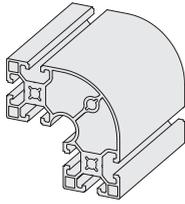



AE40-8840-6-R

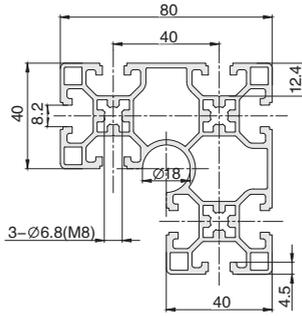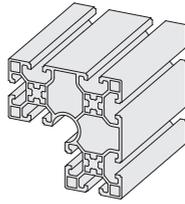



AE40-8840-8

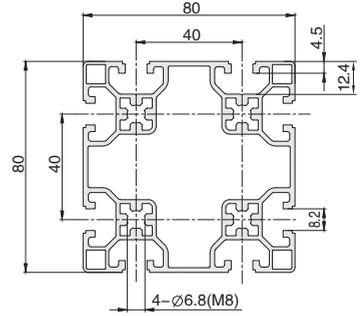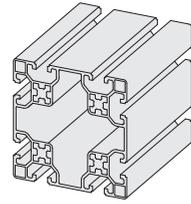



AE40-8080-8-L

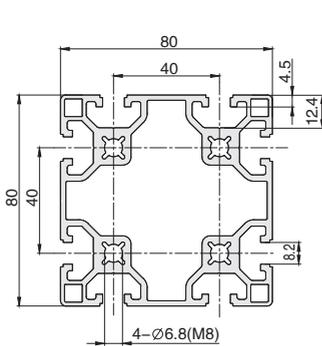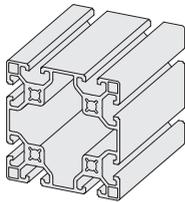

AE40-8080-8

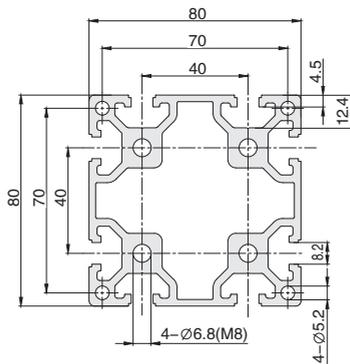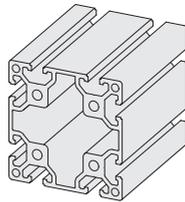




AE40-8080-8-H

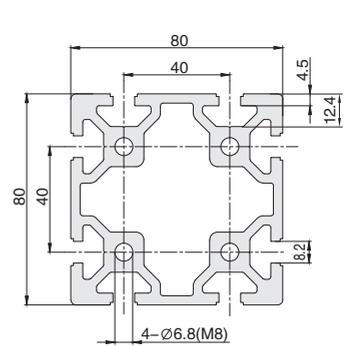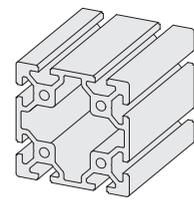


AE40-8080-8-SH



■ 产品特点：适用于中度负载结构：机器结构框架、物料车、工作台、工厂车间隔断展示架等。

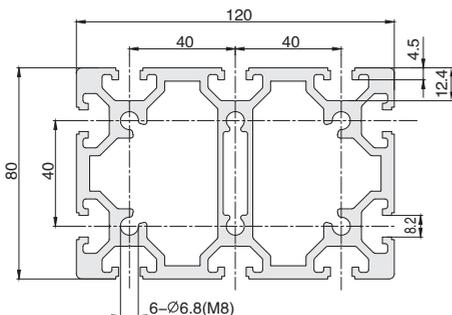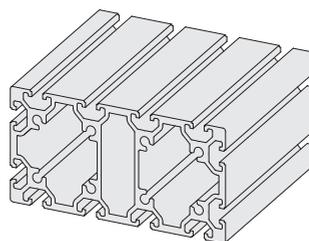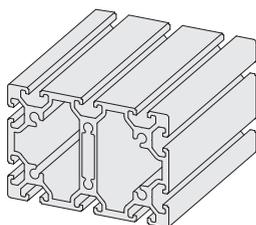

AE40-80120-10

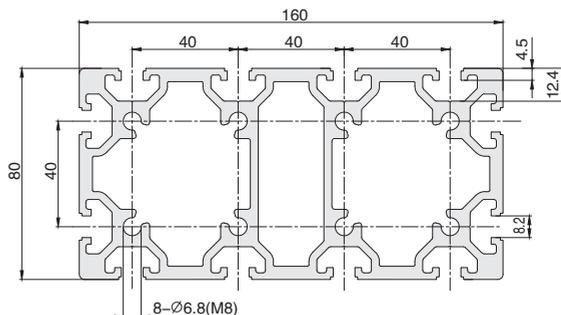

AE40-80160-12

订购编号	产品描述	截面积 (mm <sup>2</sup> )	惯性矩 I <sub>x</sub> (cm <sup>4</sup> )	惯性矩 I <sub>y</sub> (cm <sup>4</sup> )	弯矩 W <sub>x</sub> (cm <sup>3</sup> )	弯矩 W <sub>y</sub> (cm <sup>3</sup> )	米重 (kg/m)
AE40-4040-2-R-□	40 系列 40X40 2 槽 R 型	521.71	5.71	8.00	2.86	4.00	1.44
AE40-4040-2-N-□	40 系列 40X40 2 槽 N 型	559.17	8.18	8.35	4.09	4.18	1.54
AE40-4040-3-□	40 系列 40×40 3 槽	564.44	8.19	8.26	4.10	4.13	1.55
AE40-4430-2-□	40 系列 2 槽 30 度	585.71	8.53	8.93	4.27	4.47	1.61
AE40-4445-2-□	40 系列 2 槽 45 度	584.25	8.54	8.93	4.27	4.46	1.61
AE40-4460-2-□	40 系列 2 槽 60 度	585.11	8.54	8.97	4.27	4.49	1.61
AE40-4040-4-SL-□	40 系列 40×40 4 槽 超轻型	450.50	7.23	7.23	3.62	3.62	1.24
AE40-4040-4-L-□	40 系列 40×40 4 槽 轻型	469.11	7.17	7.17	3.58	3.58	1.29
AE40-4040-4-□	40 系列 40×40 4 槽	582.32	8.47	8.47	4.23	4.23	1.60
AE40-4040-4-H-□	40 系列 40×40 4 槽 重型	704.22	11.10	11.10	5.55	5.55	1.94
AE40-4060-4-□	40 系列 40×60 4 槽	780.54	11.73	24.20	5.87	8.07	2.15
AE40-4080-4-□	40 系列 40×80 4 槽	1027.01	16.08	62.75	8.04	15.69	2.83
AE40-4080-6-SL-□	40 系列 40×80 6 槽 超轻型	790.32	13.93	50.51	6.96	12.63	2.18
AE40-4080-6-L-□	40 系列 40×80 6 槽 轻型	863.84	14.67	56.07	7.33	14.02	2.38
AE40-4080-6-□	40 系列 40×80 6 槽	1040.45	16.20	63.61	8.10	15.90	2.87
AE40-4080-6-H-□	40 系列 40×80 6 槽	1237.39	19.91	79.48	9.96	19.87	3.41
AE40-40120-8-□	40 系列 40×120 8 槽	1500.04	23.94	202.57	11.97	33.76	4.13
AE40-40160-10-□	40 系列 40×160 10 槽	1957.67	31.67	461.34	15.84	57.67	5.39
AE40-40160-10-H-□	40 系列 40×160 10 槽 重型	2284.29	37.81	549.83	18.90	68.73	6.29
AE40-8840-6-R-□	40 系列 80×80 6 槽 R 型	1256.92	33.92	109.00	8.48	27.25	3.46
AE40-8840-8-□	40 系列 80×80 8 槽 L 型	1302.38	50.65	102.22	12.66	25.56	3.59
AE40-8080-8-□	40 系列 80×80 8 槽	1571.39	111.84	111.84	55.92	27.96	4.33
AE40-8080-8-L-□	40 系列 80×80 8 槽 轻型	1316.28	93.43	93.43	23.36	23.36	3.63
AE40-8080-8-H-□	40 系列 80×80 8 槽 重型	1944.30	137.41	137.41	34.35	34.35	5.35
AE40-8080-8-SH-□	40 系列 80×80 8 槽 超重型	2257.94	164.31	164.31	41.08	41.08	6.22
AE40-80120-10-□	40 系列 80×120 10 槽	2700.15	212.73	431.38	106.37	71.90	7.44
AE40-80160-12-□	40 系列 80×160 12 槽	3457.38	277.84	924.94	138.92	115.62	9.52

▲ “□”代表长度，详见技术信息。