


# 50/60 系列铝型材

## 铝型材

### 铝型材

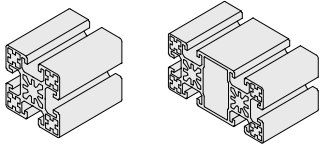


按图定制

自制 库存


材质	表面处理
A6063-T5	喷砂氧化

- 适用于重负载结构。
- ▲ 如需要进行追加工艺, 请参考技术信息。
- ▲ 长度  $L \leq 6000\text{mm}$ , 整根订购可不填。


08  
50/60  
系列

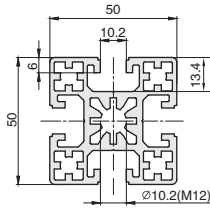


AE50-5050-4

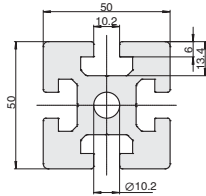


AE50-5050-4-H

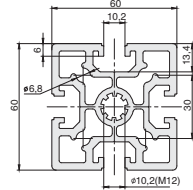


AE60-6060-4

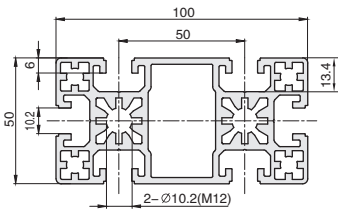


AE50-50100-6

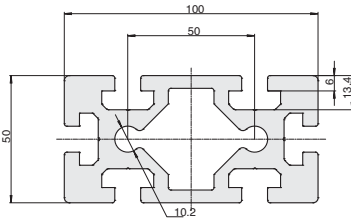

AE50-50100-6-H

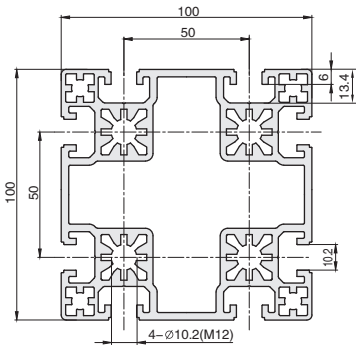

AE50-100100-8

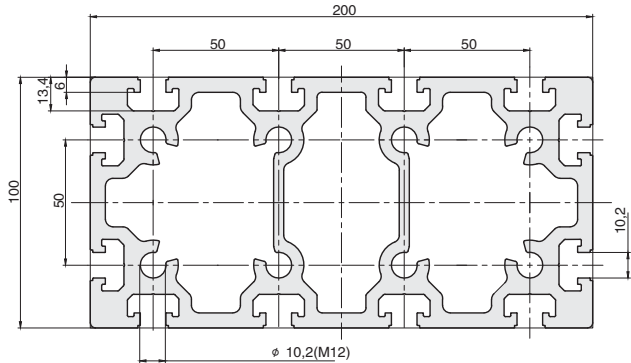

AE50-100200-12

代号	产品描述	截面积 (mm <sup>2</sup> )	惯性矩 I <sub>x</sub> (cm <sup>4</sup> )	惯性矩 I <sub>y</sub> (cm <sup>4</sup> )	弯矩 W <sub>x</sub> (cm <sup>3</sup> )	弯矩 W <sub>y</sub> (cm <sup>3</sup> )	参考米重 (kg/m)
AE50-5050-4	50 系列 50×50 4 槽	967.91	22.24	22.24	8.89	8.89	2.67
AE50-5050-4-H	50 系列 50×50 4-H 槽	1580.164	37.630	37.630	15.052	15.052	4.27
AE50-50100-6	50 系列 50×100 6 槽	1644.82	40.29	164.82	16.12	32.96	4.53
AE50-50100-6-H	50 系列 50×100 6-H 槽	2488.119	65.740	65.740	26.296	26.296	6.72
AE50-100100-8	50 系列 100×100 8 槽	2733.05	294.13	294.13	58.83	58.83	7.53
AE50-100200-12	50 系列 100×200 12 槽	6358.36	796.13	2751.82	1592.26	2751.82	17.23
AE60-6060-4	60 系列 60×60 4 槽	1456.4	51.83	51.83	17.28	17.28	3.96