

旋钮

三角旋钮·抗老化





大批量
订购
bulk order

■ 三角旋钮·抗老化



① 代号	类型	[M] 材质		[S] 表面处理
		握柄部	螺纹部	螺纹部
TKCPNB	抗老化	内螺纹型	S45C	镀锌
TKCPNC			SUS303	-
TKCPWC		外螺纹型	SWCH10R	镀锌
TKCPWD			SUS303	-

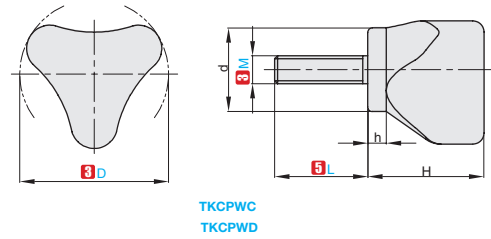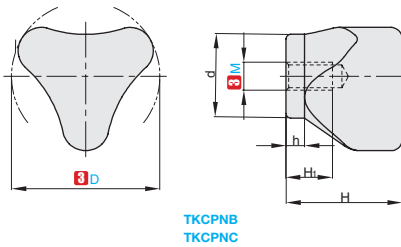

订购编号示例

① 代号	-	② M	-	③ D	-	④ L	-	⑤ 握柄部颜色
TKCPWC	-	M3	-	D16	-	L10	-	E
TKCPNB	-	M4	-	D16	-	-	-	E



型号		③ D	⑤ 握柄部颜色	d	H	H ₁	h	参考重量 (kg/pcs)
① 代号	② M							
TKCPNB TKCPNC	4	16	E (亚光黑) Y (亚光银) J (亚光橙) B (亚光蓝) H (亚光黄)	9	12.5	5	2	0.01
	5							0.009
	6							0.011
	5	25		10	14	6	2.5	0.01
	6							0.012
	6							0.011
	8	32		12	15.5	8	3	0.017
	8							0.025
	10							0.039
				40		16	21	8
				19.5	25	10		

型号		③ D	④ L	⑤ 握柄部颜色	d	H	H ₁	h	参考重量 (kg/pcs)
① 代号	② M								
TKCPWC TKCPWD	3	16	10 16	E (亚光黑) Y (亚光银) J (亚光橙) B (亚光蓝) H (亚光黄)	9	12.5	5	2	0.009~0.010
	4		10 16						0.010~0.011
	5		10 16 20						0.011~0.013
	5	20	10 16 20		10	14	6	2.5	0.013~0.014
	6		10 16 20 25						0.013~0.016
	5		20 25						0.015~0.016
	6	25	16 20 25		12	15.5	8	3	0.016~0.017
	6		20 25						0.021~0.022
	8		16 20 25						0.034~0.037
	8	32	16 20 25 30 40 50		16	21	8	4	0.048~0.059
8	20 25 30 40 50		0.067~0.082						
10	20 25 30 40 50								
		40		19.5	25	10			



小单	中大单	大单
1-50	51-100	101-
通常	7 工作日	现询



1~9	10~
100%	现询

G1
门把手/合页/手柄/手轮