


滑动式方形插销




■ 中程·旋转式开关




RoHS

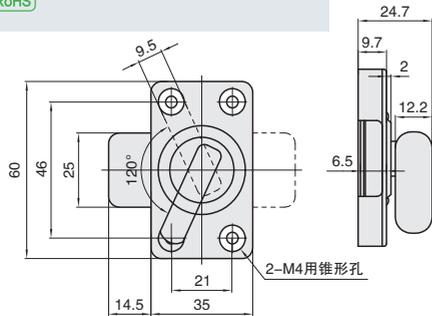

①代号	类型	④材质	⑤表面处理
LCFSMD	中程 旋转式开关	SUS304	拉丝

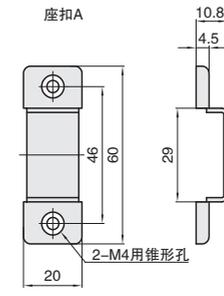

LCFSMD

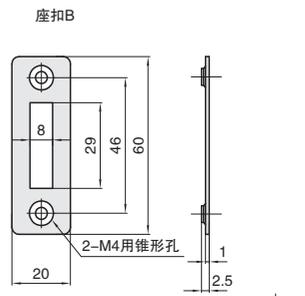

视角标准：第一视角




①代号 - ②规格
LCFSMD - 60

型号		标配件	参考重量(kg/pcs)
①代号	②规格		
LCFSMD	60	座扣A (1PCS) 座扣B (1PCS)	0.108

■ 中程·弹片式锁定



①代号	类型	④材质	⑤表面处理
LCFSMA	弹片式锁定 中程	SUS304	震动抛光

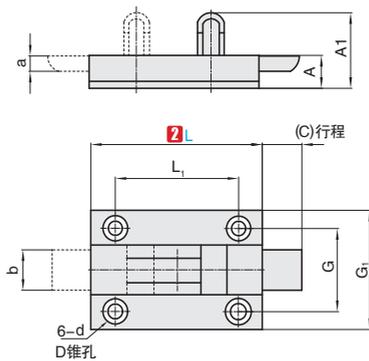

LCFSMA

视角标准：第一视角



①代号 - ②L
LCFSMA - L5 0

型号		L ₁	G ₁	G	G ₂	G ₃	E	A ₁	A	b	C	F	a	锥孔		参考重量(kg/pcs)
①代号	②L													d	D	
LCFSMA	50	34	38	25	38	28	12	27	12	13	12.5	12.5	4	3.5	7	0.06
	65	47	45	31	45	32	15	28	12.5	15	15	13.5	5	4.2		0.1



数量分类	小单	中大单	大单
数量	1~50	51~100	101~
交货期	通常	7工作日	现询



数量	1~9	10~
价格	100%	另行报价

G1 手柄/手轮/拉手
合页/门组件