



不锈钢蝶形合页

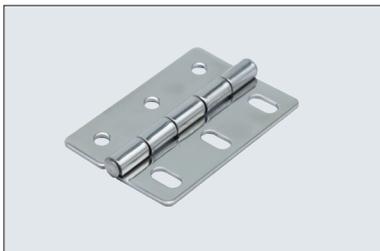

①代号 HGPSFQ	类型 圆孔+腰孔型	性价比 经济型	④材质 SUS304	⑤表面处理 镜面抛光
---------------	--------------	------------	---------------	---------------

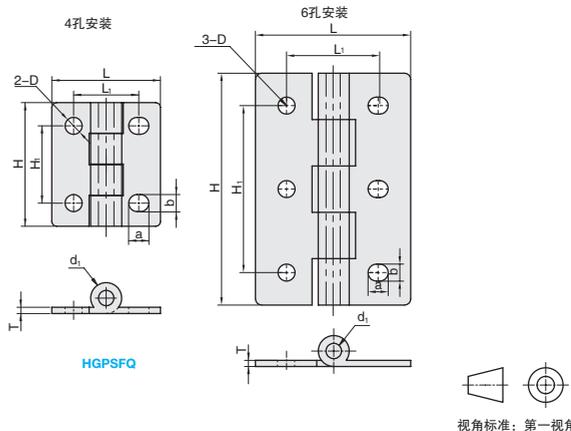

G1 手柄/手轮/拉手
合页/门组件



①代号 - ②规格
HGPSFQ - A35

型号		安装孔数	L	H	L ₁	H ₁	T	D	a	b	d ₁	负载 (kg)	参考重量 (kg/pcs)
①代号	②规格												
HGPSFQ	A35	4孔安装	35	40	21	25	2	5.5	6.5	5.5	5	9	0.03
	A47		47	47	32	30			10	6.5	6	12	0.05
	A61		61	58	42	37	3	6.5	6.5	6	25	0.06	
	A50	6孔安装	50	75	30	54	2	5.5	12	6	4.5	30	0.07
	A60		60	90	38	70	3	7	7	6	50	0.16	



数量分类	小单	中大单	大单
数量	1~50	51~100	101~
交货期	通常	7工作日	现询



数量	1-9	10~
价格	100%	现询

