


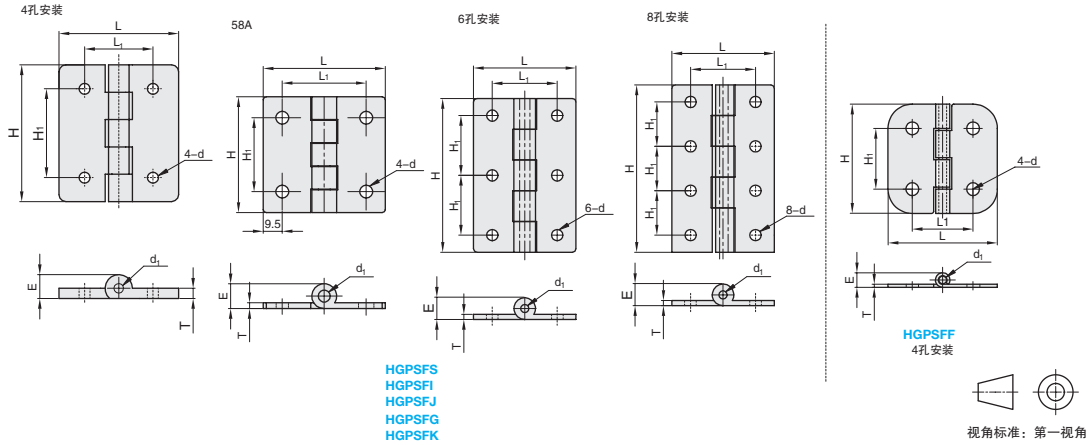

①代号	类型		性价比	④材质	⑤表面处理/颜色
HGPSFS	平型	圆孔型	经济型	SUS304	镜面抛光
HGPSFI					拉丝
HGPSFG					-
HGPSFF					研磨抛光
HGPSFK					喷漆黑色
HGPSFJ			镜面抛光		
			精密型		



G1 手柄/门组件
手柄/门拉手



①代号 - ②规格
HGPSFS - 25

订购编号示例

型号		安装孔数	L	H	L ₁	H ₁	T	E	d	d ₁	分段数	负载 (kg)			
HGPSFS	25	4孔安装	20	25	12	16	0.8	3.8	3.4	2	5	1			
	30			30		22						1			
	40			40		26						6			
	50			50		34						8			
	40A	4孔安装	30	40	22	28	1.5	6.4	3.4	3	5	6			
	50A			50		36						7			
	65			65		23						4.5	13		
	75	6孔安装	50	75	30	27	2	8	5.3	4	5	15			
	90			90		35						25			
	100	8孔安装	60	100	38	26	3	12	6.4	6	5	30			
HGPSFI HGPSFK HGPSFJ	40	4孔安装	35	40	21	25	2	9	5.5	5	5	9			
	47			47		32						30	12		
	58			58		42						37	25		
	58A			58		37						3	12.5	6.5	6
	70	6孔安装	35	70	21	25	2	9	5.5	5	5	30			
	65			65		25						11			
	77			77		32						30	9	5	15
	95			95		42						37	3	12	6.5
113	8孔安装	80	113	47	43	3	12	6	4	40					
HGPSFG	25	4孔安装	32	25	20	13	1.5	6.3	3.4	3	3	3			
	30			30		16						4			
	40			40		24						6			
	50			50		30						7			
	50A	6孔安装	35	50	22	34	2	8.5	4.2	4	4	9			
	65			65		24						10			
	75			75		28						11			
	90			90		35						13			
100	8孔安装	32	100	20	26	1.5	6.3	3.4	3	5	15				
HGPSFF	45	4孔安装	45	45	25	25	1.2	6	5.3	3.2	4	7			



数量分类	小单	中大单	大单
数量	1-50	51-100	101~
交货期	通常	7工作日	现询



数量	1-9	10~
价格	100%	现询