



高品质产品




交期缩短




大批量订单




①代号	类型	④材质	⑤表面处理
HGPZOA	对称型	ZDC	镀珍珠镍
HGPZOB			银珍珠镍
HGPZOC			喷砂镀铬

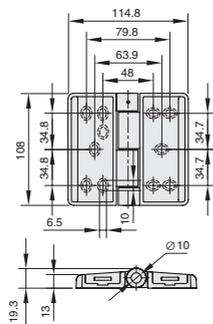


HGPZOA
横竖向腰孔型

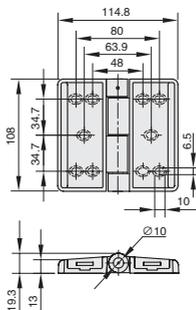

HGPZOB
横向腰孔型

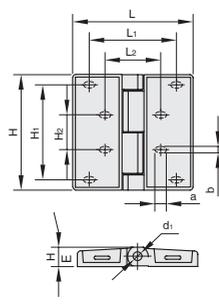

HGPZOC
横向腰孔型

 

视角标准：第一视角



①代号 - ②规格
HGPZOC - 63

订购编号示例

型号		L	L ₁	L ₂	H	H ₁	H ₂	E	a	b	d ₁	负载(kg)	参考重量(kg/pcs)
HGPZOC	②规格 63	63	45.4	30.4	60	40	20	11.5	5.5	4.2	6	50	0.15
	86	86	62	42	80	55	25	14.5	8	5.2	8	70	0.32
	104	104	75	48	100	82	30	17	10.3	5.8	8	90	0.56

型号		参考重量(kg/pcs)
①代号 HGPZOA	②规格 108	0.66



数量分类	小单	中大单	大单
数量	1-50	51-100	101~
交货期	通常	7工作日	现询



数量	1-9	10~
价格	100%	现询

G1
手柄
合页
门组件
拉手

