

圆型拉手

定位型·内装型 / 定位型



大批量
订购
bulk order

■定位型·内装型




①代号	材质	表面处理
PHYBSB	1215	电泳(黑色)
PHYBSC	12515	镀铬
PHYBSD	SUM22L 或 SUM24L	镀铬
PHYSSB	SUS304	镜面抛光


订购编号示例

①代号	-	② D	-	③ L	-	④ H
PHYBSB		D6.5		L100		H51.5


型号				M	参考重量 (kg/pcs)
①代号	② D	③ L	④ H		
PHYBSB	6.5	100	51.5	M6	0.07
PHYBSC		101.5			0.08
PHYBSD PHYSSB	10	80	37	M5	0.07
		100			0.08
		110			0.09
		120			0.10
		125			0.10
		160			0.12
		200			0.15
		250			0.18

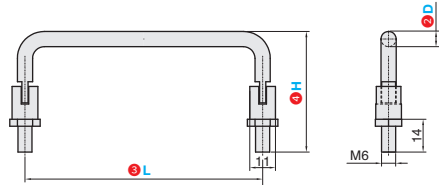

PHYBSB
PHYBSC

 

PHYBSD
PHYSSB

 

小单	中大单	大单
1-50	51-100	100~
通常	7 工作日	现询



1-9	10~
100%	现询

■定位型




①代号	类型	橡胶套	材质	表面处理
PHYBSE	带螺母型	无	Q235	镀铬
PHYSSC			SUS304	镜面抛光
PHYSSD				滚磨抛光
PHYBSF		有	Q236	镀铬
PHYSSE			SUS305	镜面抛光
PHYSSF				滚磨抛光


订购编号示例

①代号	-	② L
PHYBSE	-	L75A


型号								
①代号	② L	D	M	H	H ₁	参考重量 (kg/pcs)		
PHYBSE PHYSSC PHYSSD	75A	8	6	40	15	0.05		
	90A					0.06		
	100A					0.07		
	(110)	10	0.12					
	(120)		0.125					
	120A	8	0.08					
	(150)	12	8	50	20	0.235		
	(188)					0.27		
(238)	0.32							
(288)	0.365							
PHYBSE	100	9	6	40.5	15	0.07		
	135					0.09		
	155					0.11		
型号								
①代号	② L	D	D ₁	B	M	H	H ₁	参考重量 (kg/pcs)
PHYBSF	100		12.7	77		15		0.13
PHYSSE	120	9	18	90	6	40	18	0.14
PHYSSF								

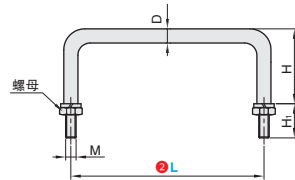

PHYBSE
PHYSSC
PHYSSD

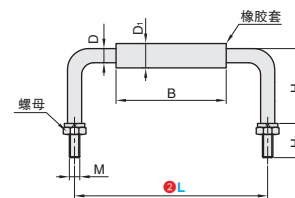

PHYBSF
PHYSSE
PHYSSF

 

小单	中大单	大单
1-50	51-100	100~
通常	7 工作日	现询



1-9	10~
100%	现询