




固定手柄

■标准型外螺纹安装

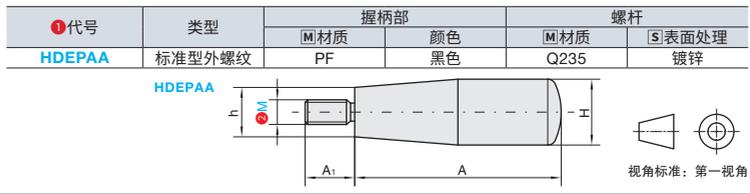

①代号 - ②M
HDEPAA - M6

①代号	型号						参考重量 (kg/pcs)
	②M	A	A ₁	H	h		
HDEPAA	6	50	12	16	12	0.02	
	8	63	14	18	14	0.05	
	10	80	16	26	20	0.07	
	12	100	18	28	22	0.11	




数量分类	小单	中大单	大单
数量	1-50	51-100	100~
交货期	通常	7工作日	现询



数量	1-9	10~
价格	100%	现询

■标准型

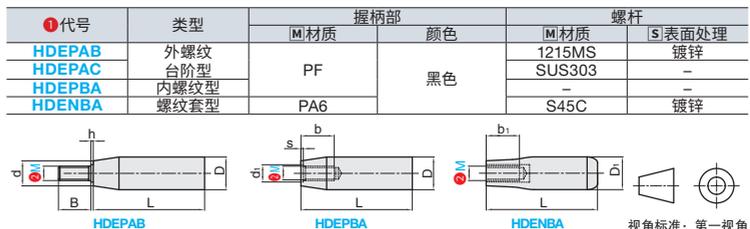

①代号 - ②M
HDEPAB - M6

①代号	②M	型号											参考重量(kg/pcs)		
		L	L (仅HDENBA适用)	B	h	S	b	b ₁	D	D ₁	d	d ₁	HDEPAB	HDEPBA	HDENBA
HDEPAB	6	40	65	13	1.5	1.8	20	12	17	19	12	6.5	0.016	0.01	0.03
	8	50	80	16	2	4.5	26	16	21	24	17	8.5	0.032	0.2	0.04
HDEPBA	10	65	80	20	5	-	33	20	25	24	20	10.5	0.061	0.037	0.045
	12	85	95	25			40	24	28	28	21	12.5	0.1	0.061	0.065




数量分类	小单	中大单	大单
数量	1-50	51-100	100~
交货期	通常	7工作日	现询



数量	1-9	10~
价格	100%	现询

■长型外螺纹安装

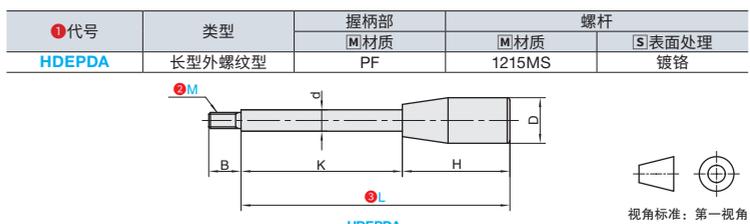

①代号 - ②M - ③L - ④握柄颜色
HDEPDA - M6 - L63 - E

①代号	型号							参考重量 (kg/pcs)	
	②M	③L	④握柄颜色	B	d	D	L		
HDEPDA	6	63	E(黑色) F(红色)	10	8	16	35	0.06	
		80						0.09	
		100						0.12	
	8	80			12	10	18	40	0.08
		100							0.10
		125							0.14
	10	100		14		12	22	50	0.12
		125							0.14
		160							0.17
	12	125			16	16	27	60	0.16
		160							0.19
		200							0.25



数量分类	小单	中大单	大单
数量	1-50	51-100	100~
交货期	通常	7工作日	现询



数量	1-9	10~
价格	100%	现询