


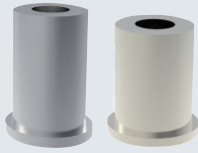

台阶调整环




按图定制


①代号	L尺寸公差	④材质	⑤表面处理
MCAWT	0	一般结构用钢	四氧化三铁保护膜
MCBWT	-0.1	不锈钢	无电解镍
MCEWT			-
MCAXT	+0.1	一般结构用钢	四氧化三铁保护膜
MCBXT	0	不锈钢	无电解镍
MCEXT			-

▲ 如对防锈有要求，请优先选用不锈钢材质或无电解镍产品。


L尺寸公差 ${}_{-0.1}^0$

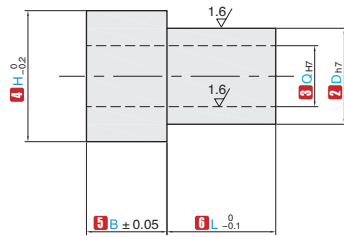

L尺寸公差 ${}_{0}^{+0.1}$

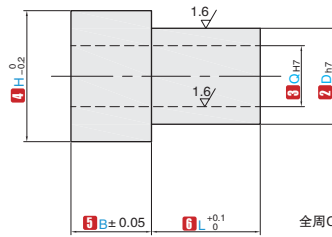

全周C0.5以下

 

视角标准：第一视角



①代号 - ②D - ③Q - ④H - ⑤B - ⑥L
MCAWT - D7.0 - Q3.0 - H3.0 - B4.0 - L10.0

①代号	②D 指定单位0.5mm	③Q 指定单位0.5mm	④H 指定单位0.5mm	⑤B 指定单位0.1mm	⑥L 指定单位0.1mm
L尺寸公差 0 -0.1 MCAWT MCBWT MCEWT	5.0~10.0	2.0~8.0 (Q≤D-2)	7.0~16.0 (D+2≤H≤D+6)		1.0~5.0
					5.1~10.0
					10.1~25.0
					25.1~40.0
L尺寸公差 +0.1 0 MCAXT MCBXT MCEXT	10.5~20.0	2.0~18.0 (Q≤D-2)	12.5~26.0 (D+2≤H≤D+6)		1.0~5.0
					5.1~10.0
					10.1~25.0
					25.1~40.0
	20.5~30.0	2.0~28.0 (Q≤D-2)	22.5~40.0 (D+2≤H≤D+6)	1.0~20.0	1.0~20.0
					20.1~30.0
					30.1~40.0
					40.1~50.0
	30.5~40.0	6.0~36.0 (Q≤D-2)	32.5~50.0 (D+2≤H≤D+6)		1.0~20.0
					20.1~30.0
					30.1~40.0
					40.1~50.0
	40.5~50.0	10.0~44.0 (Q≤D-2)	42.5~60.0 (D+2≤H≤D+6)		1.0~20.0
					20.1~30.0
					30.1~40.0
					40.1~50.0

▲ 加工条件①L+B≤Q×8②Q≥8且L+B≥Q×4时，带有中间退刀槽。



交货期

5天发货

数量分类	标准订单	特殊订单
	小单	大单
数量	1~200	201~
交货期	5天发货	另行报价

▲ 常州工厂发货。

▲ 部分产品型号 7 天发货，请以报价为准。



爱安特自营商城焕新登场，线上下单，疾速送达



400-6699-428



www.ant-fa.com

A6
垫圈、轴环