

开口式固定环


端面孔型



端面孔型



类型	M 材质	S 表面处理	A 附件
SCABAB	一般结构用钢	四氧化三铁保护膜	1个内六角螺栓
SCAEAB		无电解镀镍	1个内六角螺栓(不锈钢)
SCANAB	不锈钢	-	

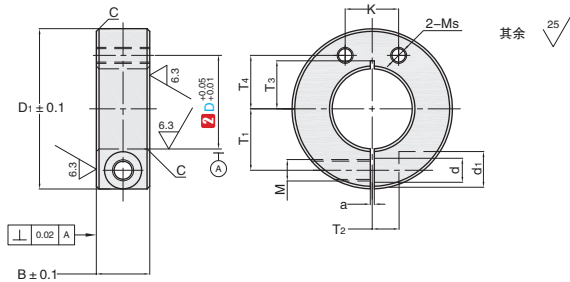

订购编号示例

① 代号 - ② D - ③ B
 SCABAB - D12 - B10

① 代号	内径 ② D	③ B	主要尺寸												
			D_1	M(粗牙螺纹)	Ms(粗牙)	d	d_1	K	a	T_1	T_2	T_3	T_4	C	
SCABAB SCAEAB SCANAB	8	10	25	M4	M3	4.5	7.5	8	1.5	8	8	5	9	8	0.5
	10		M4		M4					10	9	5	10	10	
	12									11.5	6	12	12		
	15		M5	M5	5.5	9	12	12		6	12	12			
	16						14	7		13	14				
	20	17					7	18		17					
	25	12	45	M6	M6	6.6	12	20		16	17	7	18	17	
	30	15	55							20	20	10	20	20	

A3
固定环