 
 



| ①代号     | 产品类型 |       | 宽度 | 材质     |
|---------|------|-------|----|--------|
| SRBE27Y | 二节式  | 3/4伸展 | 27 | SUS304 |

- ▲ 按根销售。
- ▲ 滑轨安装请使用尺寸4盘头自攻螺钉或M4盘头小螺钉。
- ▲ 安装简介及示例请参考 OP.1921~1922。
- ▲ 最大负载可达到26Kg/副。
- ▲ 承重与负载仅供参考。



视角标准：第一视角

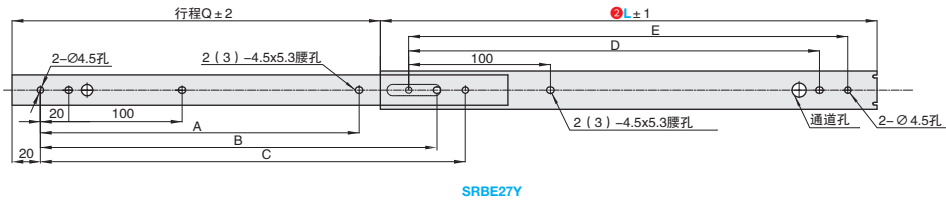

①代号 - ②L  
SRBE27Y - L350

| ①代号     | 型号        | 行程Q | A   | B   | C   | D   | E   | 额定负载 (N/2个) | 参考重量 (kg/pcs) |
|---------|-----------|-----|-----|-----|-----|-----|-----|-------------|---------------|
|         | ②L (滑轨长度) |     |     |     |     |     |     |             |               |
| SRBE27Y | 200       | 135 | -   | 140 | 160 | 140 | 160 | 260         | 0.17          |
|         | 250       | 185 | 150 | 190 | 210 | 190 | 210 |             | 0.21          |
|         | 300       | 222 | 190 | 240 | 260 | 240 | 260 |             | 0.25          |
|         | 350       | 260 | 225 | 290 | 310 | 290 | 310 |             | 0.29          |
|         | 400       | 297 | 265 | 340 | 360 | 340 | 360 |             | 0.33          |
|         | 450       | 334 | 300 | 390 | 410 | 390 | 410 |             | 0.37          |
|         | 500       | 371 | 337 | 440 | 460 | 440 | 460 |             | 0.41          |



| 数量分类 | 小单   | 中大单    | 大单   |
|------|------|--------|------|
| 数量   | 1~50 | 51~100 | 101~ |
| 交货期  | 通常   | 7工作日   | 现询   |



| 数量 | 1~9  | 10~ |
|----|------|-----|
| 价格 | 100% | 现询  |

