


①代号	产品类型		宽度	材质	表面处理
SRBE35	三节式	全长伸展	35.3	SPCC	镀锌

- ▲ 按根销售。
- ▲ 滑轨安装请使用M4圆头小螺丝或夹紧小螺丝。
- ▲ 安装简介及示例请参考 OP.1921-1922。
- ▲ 最大负载可达到52.9Kg/副。
- ▲ 承重与负载仅供参考。

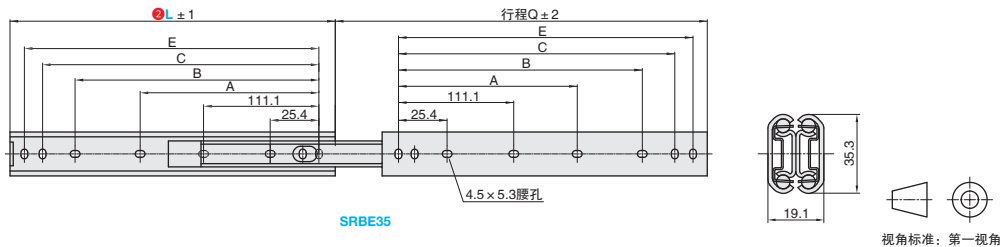

视角标准：第一视角



①代号 - ②L
SRBE35 - L305

①代号	型号		行程Q	A	B	C	E	额定负载 (N/2个)	参考重量 (kg/pcs)
	②L (滑轨长度)								
SRBE35	305		324.2	—	149.2	260.3	273	500	0.48
	356		375.4	—	200	311.1	323.8	529	0.52
	406		424.6	—	250.8	361.9	374.6	500	0.56
	457		475.8	212.7	301.6	412.7	425.4	461	0.66
	508		527	238.1	352.4	463.5	476.2	451	0.74
	559		578.2	263.5	403.2	514.3	527	102	0.86
	610		629.4	288.9	454	565.1	577.8	353	0.97
	660		678.6	314.3	504.8	615.9	628.6	333	1.19
	711		729.8	339.7	555.6	666.7	679.4	294	1.43



数量分类	小单	中大单	大单
数量	1-50	51-100	101~
交货期	通常	7工作日	现询



数量	1-9	10~
价格	100%	现询

