


①代号	产品类型		宽度	材质	表面处理
SRBG37	三节式	全长伸展	37	SPCC	镀锌

- ▲ 按根销售。
- ▲ 滑轨安装请使用M4圆头小螺丝或夹紧小螺丝。
- ▲ 安装简介及示例请参考 OP.1921-1922。
- ▲ 最大负载可达到35Kg/副。
- ▲ 承重与负载仅供参考。



SRBG37

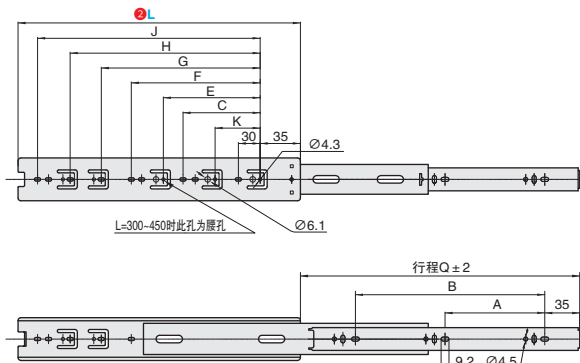

视角标准：第一视角



①代号 - ②L
SRBG37 - L450

型号		行程Q	A	B	C	E	F	G	H	J	K	额定负载 (N/副)
①代号	②L (滑轨长度)											
SRBG37	250	250	160	-	-	-	-	-	160	-	-	220
	300	300	96	192	160	224	-	-	-	-	64	240
	350	350	128	256	160	224	-	-	-	-	64	260
	400	400	128	320	160	224	-	-	288	-	64	280
	450	450	160	352	160	224	-	-	352	-	64	300
	500	500	192	416	160	224	288	352	416	-	64	320
	550	550	224	448	160	224	288	352	416	480	64	350



数量分类	小单	中大单	大单
数量	1-50	51-100	101~
交货期	通常	7工作日	现询



数量	1-9	10~
价格	100%	现询

G5 工业滑轨



爱安特自营商城焕新登场, 线上下单, 疾速送达



400-6699-428



www.ant-fa.com