 





①代号	产品类型		宽度	材质
SRSE35	二节式	3/4伸展	35.3	SUS304

- ▲ 按根销售。
- ▲ 滑轨安装请使用尺寸4盘头自攻螺钉或M4盘头小螺钉。
- ▲ 安装简介及示例请参考 OP.1921-1922。
- ▲ 最大负载可达到49Kg/副。
- ▲ 承重与负载仅供参考。

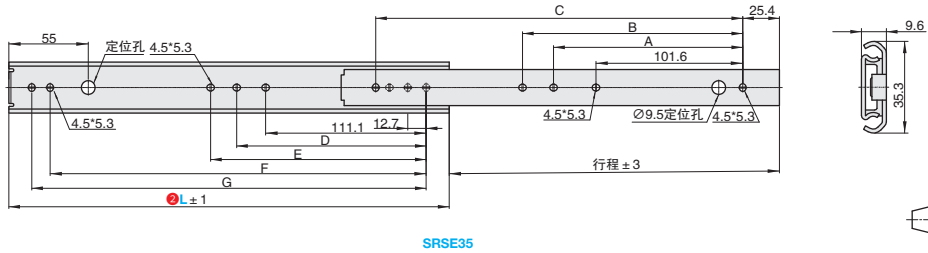

①代号 - ②L
SRSE35 - L508

型号		行程Q	A	B	C	D	E	F	G	额定负载 (N/2个)	参考重量 (kg/pcs)
①代号	②L (滑轨长度)										
SRSE35	304.8	228.6	-	152.4	254	-	149.2	260.3	273	490	0.31
	355.6	279.4	-	203.2	304.8	-	200	311.1	323.8	470	0.36
	406.4	304.8	-	254	355.6	-	250.8	361.9	374.6	430	0.41
	457.2	330.2	203.2	304.8	406.4	212.7	301.6	412.7	425.4	410	0.46
	508	381	228.6	355.6	457.2	238.1	352.4	463.5	476.2	370	0.51
	558.8	406.4	254	406.4	508	263.5	403.2	514.3	527	340	0.56
	609.6	431.8	279.4	457.2	558.8	288.9	454	565.1	577.8	300	0.61
	660.4	482.6	304.8	508	609.6	314.3	504.8	615.9	628.6	370	0.66
	711.2	508	330.2	558.8	660.4	339.7	555.6	666.7	679.4	250	0.71



数量分类	小单	中大单	大单
数量	1-50	51-100	101~
交货期	通常	7工作日	现询



数量	1-9	10~
价格	100%	现询

