



缓冲器





BAC0806-BAC2580

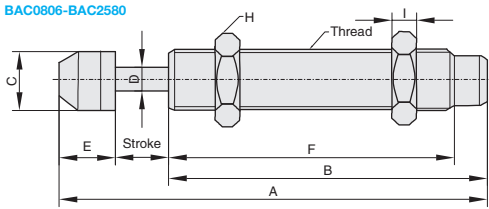

BAC2540

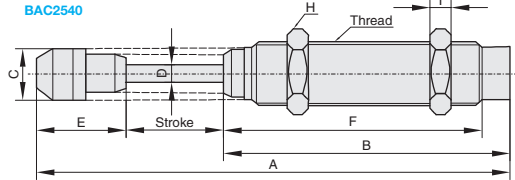

BAC3660

 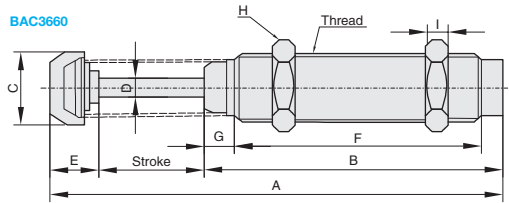

视角标准：第一视角



①型号

BAC1005-1(N)

●型号	行程(mm)	每次最大吸收能量(kgf.m)	有效重量(kg)	冲击速度(m/s)	每小时吸收能量(Nm)	使用温度(°C)	重量(g)
BAC0806-1(N)	6	1.8	0.8~5.6	2	8800	-10~+80	12
BAC0806-2(N)			2.5~10	1.2	8800	-10~+80	12
BAC0806-3(N)			5.5~22	0.8	8800	-10~+80	12
BAC1005-1(N)	5	3	1~4.2	2.4	10800	-10~+80	14
BAC1005-2(N)			2.5~8	1.2	10800	-10~+80	14
BAC1005-3(N)			10~35	0.8	10800	-10~+80	14
BAC1008-1(N)	8	3.3	1~4.4	2.6	15200	-10~+80	21.1
BAC1008-2(N)			2.8~10	1.5	15200	-10~+80	21.1
BAC1008-3(N)			10~40	0.8	15200	-10~+80	21.1
BAC1210-1(N)	10	6	1.8~12	2.6	17640	-10~+80	37.4
BAC1210-2(N)			5.3~18.7	1.5	17640	-10~+80	37.4
BAC1210-3(N)			12~75	0.8	17640	-10~+80	37.4
BAC1412-1(N)	12	16	0.4~32	2.6	30000	-10~+80	61.5
BAC1412-2(N)			14~50	1.5	30000	-10~+80	61.5
BAC1412-3(N)			56~200	0.8	30000	-10~+80	61.5
BAC1415-1(N)	15	18	5~27	2.6	36000	-10~+80	66.2
BAC1415-2(N)			17~62	1.5	36000	-10~+80	66.2
BAC1415-3(N)			62~280	0.8	36000	-10~+80	66.2
BAC1416-1(N)	16	20	6~43	3	36000	-10~+80	82
BAC1416-2(N)			18.5~64	1.5	36000	-10~+80	82
BAC1416-3(N)			64.8~253	0.8	36000	-10~+80	82
BAC1416-2C(N)	16	20	17~62	1.5	36000	-10~+80	80
BAC1416-3C(N)			50~250	0.8	36000	-10~+80	80
BAC1425-1(N)	25	20	6~43	3	36000	-10~+80	96
BAC1425-2(N)			18.5~64	1.5	36000	-10~+80	96
BAC1425-3(N)			64.8~253	0.8	36000	-10~+80	96
BAC2020-1(N)	20	35	9~36	3.2	42000	-10~+80	175.5
BAC2020-2(N)			23~92	2	42000	-10~+80	175.5
BAC2020-3(N)			64~575	1.2	42000	-10~+80	175.5
BAC2030-1(N)	30	45	7~27	3.2	48000	-10~+80	195.2
BAC2030-2(N)			17~70	2	48000	-10~+80	195.2
BAC2030-3(N)			48~777	1.2	48000	-10~+80	195.2
BAC2050-1(N)	50	60	10~125	3.5	63240	-10~+80	254.4
BAC2050-2(N)			18~253	2.6	63240	-10~+80	254.4
BAC2050-3(N)			55~496	1.5	63240	-10~+80	254.4

缓冲器

①型号	行程(mm)	每次最大吸收能量(kgf.m)	有效重量(kg)	冲击速度(m/s)	每小时吸收能量(Nm)	使用温度(°C)	重量(g)
BAC2525-1(N)	25	80	15~69	3.2	54000	-10~+80	332.5
BAC2525-2(N)			39~380	2	54000	-10~+80	332.5
BAC2525-3(N)			108~1733	1.2	54000	-10~+80	332.5
BAC2540-1(N)	40	120	20~106	3.5	75000	-10~+80	430
BAC2540-2(N)			50~450	2.2	75000	-10~+80	430
BAC2540-3(N)			245~1991	1	75000	-10~+80	430
BAC2550-1(N)	50	140	20~124	3.6	90000	-10~+80	470
BAC2550-2(N)			48~438	2.4	90000	-10~+80	470
BAC2550-3(N)			194~2286	1.2	90000	-10~+80	470
BAC2580-1(N)	80	198	25~198	4	120000	-10~+80	570.5
BAC2580-2(N)			44~396	3	120000	-10~+80	570.5
BAC2580-3(N)			176~1584	1.5	120000	-10~+80	570.5
BAC3660-1(N)	60	260	57~231	3	124800	-10~+80	1033.6
BAC3660-2(N)			130~813	2	124800	-10~+80	1033.6
BAC3660-3(N)			520~3250	1	124800	-10~+80	1033.6

①型号	螺纹公称	行程(mm)	A	B	C	D	E	F	G	H	I
BAC0806-1(N)	M8×1.0	6	50	38	6.6	2.9	6	33		11	4
BAC0806-2(N)			50	38	6.6	2.9	6	33		11	4
BAC0806-3(N)			50	38	6.6	2.9	6	33		11	4
BAC1005-1(N)	M10×1.0	5	38.7	27.9	8.6	2.9	6	22.9		12.7	3
BAC1005-2(N)			38.7	27.9	8.6	2.9	6	22.9		12.7	3
BAC1005-3(N)			38.7	27.9	8.6	2.9	6	22.9		12.7	3
BAC1008-1(N)	M10×1.0	8	58	43	8.8	2.9	9	38		12.7	4
BAC1008-2(N)			58	43	8.8	2.9	9	38		12.7	4
BAC1008-3(N)			58	43	8.8	2.9	9	38		12.7	4
BAC1210-1(N)	M12×1.0	10	71	50	10.5	2.9	11	46		14	5
BAC1210-2(N)			71	50	10.5	2.9	11	46		14	5
BAC1210-3(N)			71	50	10.5	2.9	11	46		14	5
BAC1412-1(N)	M14×1.5	12	99	76	12	3.8	11	67		19	5
BAC1412-2(N)			99	76	12	3.8	11	67		19	5
BAC1412-3(N)			99	76	12	3.8	11	67		19	5
BAC1415-1(N)	M14×1.5	15	102	76	12	3.8	11	67		19	5
BAC1415-2(N)			102	76	12	3.8	11	67		19	5
BAC1415-3(N)			102	76	12	3.8	11	67		19	5
BAC1416-1(N)	M14×1.5	16	106	79	12	4	11	73		19	5
BAC1416-2(N)			106	79	12	4	11	73		19	5
BAC1416-3(N)			106	79	12	4	11	73		19	5
BAC1416-2C(N)	M14×1.5	16	103	76	12	3.8	11	67		19	5
BAC1416-3C(N)			103	76	12	3.8	11	67		19	5
BAC1425-1(N)	M14×1.5	25	146	110	12	3.8	11	101		19	5
BAC1425-2(N)			146	110	12	3.8	11	101		19	5
BAC1425-3(N)			146	110	12	3.8	11	101		19	5
BAC2020-1(N)	M20×1.5	20	146	110	17.8	6	16	101		26	8
BAC2020-2(N)			146	110	17.8	6	16	101		26	8
BAC2020-3(N)			146	110	17.8	6	16	101		26	8
BAC2030-1(N)	M20×1.5	30	161	115	17.8	6	16	106		26	8
BAC2030-2(N)			161	115	17.8	6	16	106		26	8
BAC2030-3(N)			161	115	17.8	6	16	106		26	8
BAC2050-1(N)	M20×1.5	50	224.5	158.5	17.8	6	16	149.5		26	8
BAC2050-2(N)			224.5	158.5	17.8	6	16	149.5		26	8
BAC2050-3(N)			224.5	158.5	17.8	6	16	149.5		26	8
BAC2525-1(N)	M25×1.5	25	155	111	22	8	19	101		32	10
BAC2525-2(N)			155	111	22	8	19	101		32	10
BAC2525-3(N)			155	111	22	8	19	101		32	10
BAC2540-1(N)	M25×1.5	40	213	137	22	8	36	127		10	32
BAC2540-2(N)			213	137	22	8	36	127		10	32
BAC2540-3(N)			213	137	22	8	36	127		10	32
BAC2550-1(N)	M25×1.5	50	240	170	22	8	19	160		32	10
BAC2550-2(N)			240	170	22	8	19	160		32	10
BAC2550-3(N)			240	170	22	8	19	160		32	10
BAC2580-1(N)	M25×1.5(P2.0)	80	336	247	22	8	19	237		32	10
BAC2580-2(N)			336	247	22	8	19	237		32	10
BAC2580-3(N)			336	247	22	8	19	237		32	10
BAC3660-1(N)	M36×1.5	60	248	145	36	10	26	134	17	46	15
BAC3660-2(N)			248	145	36	10	26	134	17	46	15
BAC3660-3(N)			248	145	36	10	26	134	17	46	15

▲ 无需撞击头型号-N。列BAC2050-2-N