



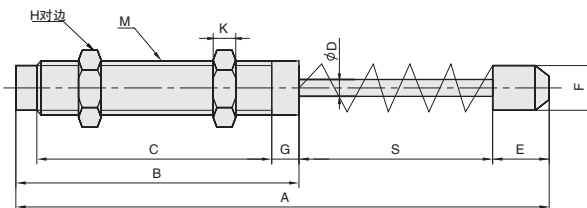


4225/4250/4275



64050/64100/64150

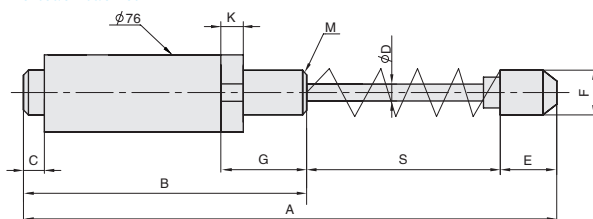

85050/85090/85125/85165

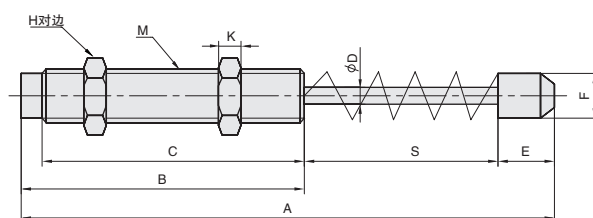

订购编号示例

1 代号 - **2** 尺寸系列
BAE - 4225

1 型号	2 尺寸系列	最高撞击速度 (m/s)	主要尺寸											最大吸收 能量 Nm	小时吸收 能量 Nm	最大有效 重量 Kg	工作温度 °C
			S (行程)	M	A	B	C	D	E	F	G	H	K				
BAE	4225	4	25	M42x1.5	186.5	127.5	88	12	35	44.5	28.5	15	15	260	125000	3000	-45~+80
	4250		50	M42x1.5	241	157	117.5	12	35	44.5	28.5	15	15	500	150000	4000	
	4275		75	M42x1.5	301.5	187.5	148	12	39	44.5	28.5	15	15	750	180000	6000	
	64050	2	50	UNF21/2-12	247.8	146	26	20	51.8	59	23	76.2	9.4	2080	185000	12727	
	64100		100	UNF21/2-12	347.8	196	26	20	51.8	59	23	76.2	9.4	4280	204000	18181	
	64150		150	UNF21/2-12	467.8	256	26	20	61.8	59	23	76.2	9.4	6150	248000	23636	
	85050		50	M85x2	265	140	48	40	98	80	-	95	16	2300	372000	37000	
	85090		90	M85x2	345	180	70	60	98	80	-	95	16	4000	652000	40000	
	85125		125	M85x2	420	216	84	82	98	80	-	95	16	5700	933000	43000	
85165	165	M85x2	514	256	100	106	98	80	-	95	16	7300	1215000	45000			