
 


1 代号	类型
LECN	条形单层信号灯

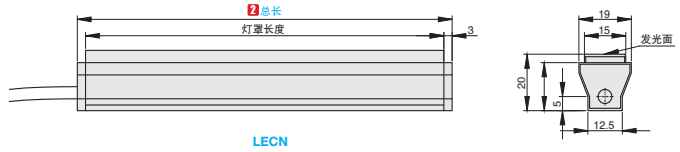

▲ 灯体安装方式为灯夹安装或者嵌入式安装。
 ▲ 此款灯默认不带灯夹, 如需附带灯夹, 请备注说明。



性能参数	
保护等级	IP40
输入电压	DC24V
输入电压范围	DC24V
色温范围	5500~6000K
灯具寿命	40000h
运行温度	-20°C ~45°C
运行湿度	10~90%
表面温度	<60°C



1 代号 - **2** 总长 - **3** 接线方式
 LECN - 130 - E

型号		3 接线方式	灯罩长度	发光面宽度	发光颜色	额定电压	外置线长
1 代号	2 总长						
LECN	130	E: 电源直接输入式(共正) N: 电源直接输入式(共负)	126	15	R Y G (红黄绿)	DC 24V	150mm
	238		234				
	346		342				
	454		450				
	670		666				
	778		774				
	994		990				
	1102		1098				
	1210		1206				
	1426		1422				
1534	1530						



数量分类	小单	中大单	大单
数量	1~50	51~100	101~
交货期	通常	7工作日	现询



数量	1-9	10~
价格	100%	现询

G4
LED
灯

