



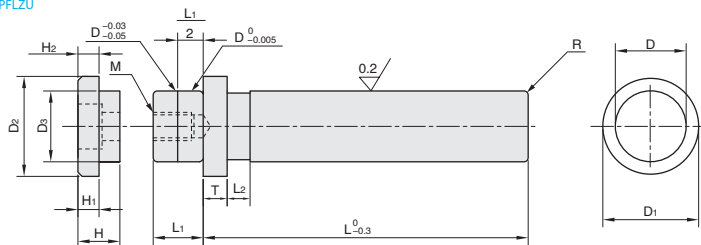


GPFLZU

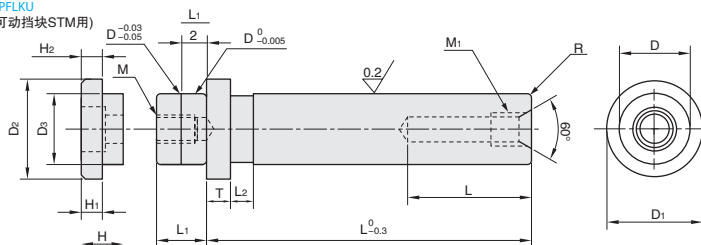

GPFLKU
(可动挡块STM用)




GPFLGU
(固定挡块STK用)

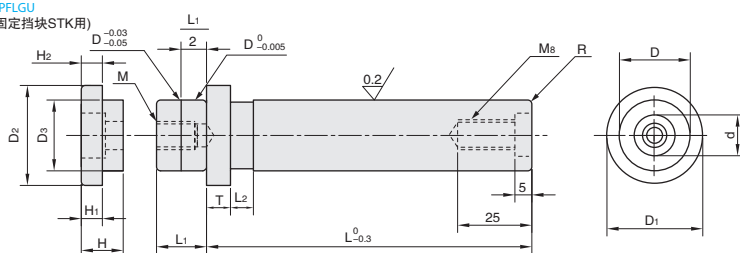


▲ 导柱采用高频淬火，中心无硬度，安装请勿使用硬物敲击。

 
■ 材质：GCr15
■ 硬度：58HRC~高频淬火
(深度1.5~2.0mm)




GPFYZU

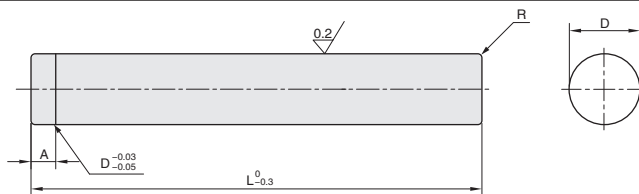

GPFYKU
(可动挡块STM用)

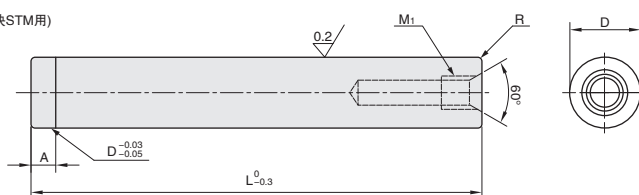


GPFYGU
(固定挡块STK用)

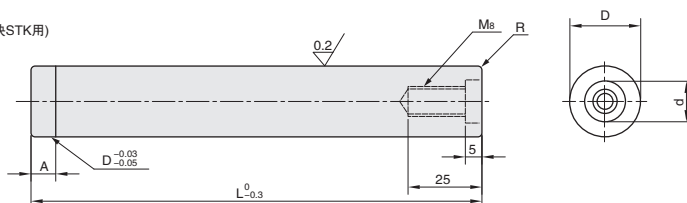

▲ 导柱采用高频淬火，中心无硬度，安装请勿使用硬物敲击。

 ■ 材质：GCr15
■ 硬度：58HRC~高频淬火
(深度1.5~2.0mm)



模架用导柱



①代号 - ②D - ③L
 GPFLZU - D20 - L180

D	D1	T	L1	L2	l	M1×P	d	A	M	R	D2	D3	H	H1	H2	附属螺栓
20	+0.020	29	5	15	38	M10×1.5	14	4	M8×18	2.0	28	19.5	14	7	8.5	TS 8-25
22	+0.015	31	8	18	42	30					21.5					
25	+0.025	35	10	20	50	35					24.5					
28	+0.025	39	10	20	60	M12×1.5	20	5	M10×22	3.5	36	27.5	16	8	10.5	TS 10-30
32	+0.020	44	12	23	70	40					31.5					
38	+0.030	53	12	27	80	49					37.5					
45	+0.025	59	15	32	90	M16×1.5	20	6	M12×27	4.0	55	44.5	18	10	12.5	ST 12-35
50	+0.035	69	15	35	100	62					49.5					
60	+0.030	79	15	42	120	72					59.5					


型式		③L																											
①型号	②D	20	80	90	100	110	120	130	140	150	160	170	180	200															
GPFLZU GPFLKU GPFLGU	22	80	90	100	110	120																							
	25	80	90	100	110	120	130																						
	28	100	110	120	130	140	150	160																					
	32	120	130	140	150	160																							
	38	140	150	160	170	180																							
	45	140	150	160	170	180																							
	50	160	170	180	200																								
60	160	170	180	200																									

型式		③L																						
①Type	②D	20	100	110	120	130	140	150	160	170	180													
GPFYZU GPFYKU GPFYGU	22	120	130	140	150	160	170	180																
	25	120	130	140	150	160	170	180																
	28	140	150	160	170	180	190	200																
	32	160	170	180	190	200	220	240																
	38	180	190	200	220	240	260																	
	45	180	190	200	220	240	260																	
	50	200	220	240	260																			
60	200	220	240	260																				


F6
模具零件



 GPFLZU-GPFLKU-GPFLGU



GPFYZU-GPFYKU-GPFYGU

 

LD

变更全长 指定单位 1mm

D	GPFLZU	GPFLKU · GPFLGU	GPFYZU	GPFYKU · GPFYGU
20	60-199	70-199	70-179	80-179
22	60-119	70-119	70-179	80-179
25	60-129	81-129	70-179	80-179
28	60-159	80-159	70-199	80-199
32	60-159	100-159	70-239	80-239
38	60-179	100-179	70-259	80-259
45	60-179	120-179	70-259	90-259
50	60-199	120-199	70-259	90-259
60	60-199	120-199	70-259	90-259



交货期

3天发货

数量分类	标准订单	特殊订单
		小单
数量	1-30	30~
交货期	通常	另行报价

- ▲常州·东莞发货。
- ▲部分产品8天发货, 请以实际报价为准。



爱安特自制模组, 火爆开售! 全零件备库, 最快 5 个工作日出货!



400-6699-428



www.ant-fa.com