

全铜快拧系列 直角铰接式接头

大批量
订购
bulk order

■直角铰接式接头


L2
气动接头

NEW
新产品



CAD
2D/3D

①代号 NGDLC	④材质 铜	⑤表面处理 镀镍
--------------	----------	-------------

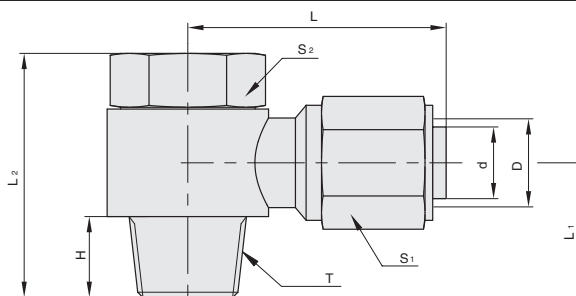

订购编号示例

①代号 - ②尺寸系列
NGDLC - 0402A

NGDLC

①代号	②尺寸系列	D	T	L	L ₁	L ₂	S ₁	S ₂	H	D×d (φ)
NGDLC	0405B	φ4	M5	17	10	19	8	8	3.6	4×φ2.5
	0401A		R1/8	20	15	25	8	12	7	
	0402A		R1/4	22	18	29	8	15	9	
	0605B	φ6	M5	21	11	19	10	8	3.6	6×φ4
	0601A		R1/8	23	15	25	10	12	7	
	0602A		R1/4	24	18	29	10	15	9	
	0603A		R3/8	25	20	33	10	19	9.5	
	0604A	R1/2	28	22.5	36	10	22	11.5		
	0801A	φ8	R1/8	25	15	25	14	12	7	8×φ5
	0802A		R1/4	26	18	29	14	15	9	
	0803A		R3/8	28	20	33	14	19	9.5	
	0804A		R1/2	30.5	22.5	36	14	22	11.5	
	1001A	φ10	R1/8	27	16	25	15	12	7	10×φ6.5
	1002A		R1/4	28	19	29	15	15	9	
	1003A		R3/8	30	20	33	15	19	9.5	
	1004A		R1/2	30	22.5	36	15	22	11.5	
1201A	φ12	R1/8	28	17	25	17	12	7	12×φ8	
1202A		R1/4	29	20	29	17	15	9		
1203A		R3/8	31	21	33	17	19	9.5		
1204A		R1/2	32	22.5	36	17	22	11.5		
1404A	φ14	R1/2	39	25.5	36	19	22	11.5	14×φ10	
1604A	φ16	R1/2	39	25.5	36	21	22	11.5	16×φ12	