


按图定制

①代号		边长	④材质	⑤表面处理	最高使用压力
前后贯通型	MALAFP	30×40	铝合金	-	1MPa(≈10.2Kgf/cm²)以下
横向不贯通型	MALAFR	50×50			
前后半贯通顶孔型	MALBFP	30×40			
横向不贯通型	MALBFR	50×50			

前后贯通型  
MALAFP  
MALAFR  
(边长30×40-50×50)

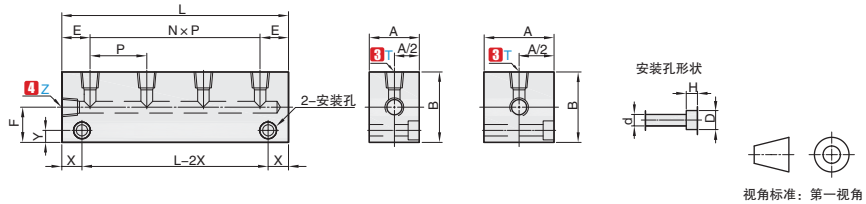

视角标准：第一视角




①代号 - ②侧面孔数K - ③T - ④Z  
MALAFR - K2 - T3 - Z3

①代号	②侧面孔数K	RC(PT)/M选择		间距P	N	T·Z 螺孔数	L	A	B	E	F	X	Y	安装孔尺寸		
		③T	④Z											d	D	h
前后贯通型 MALAFP MALAFR (30×40)	1			30	0	2	40	30	40	20	20	7.5	7	5.5	9.5	6
	2	1 (1/8)	1 (1/8)		1	3	70									
	3	2 (1/4)	2 (1/4)		2	4	100									
	④	5 (M5)	5 (M5)		3	5	130									
	⑤				4	6	160									
前后贯通型 MALAFP MALAFR (50×50)	1	1 (1/8)		40	0	2	50	50	50	25	25	8.5	8.5	8.5	14	9
	2	2 (1/4)	2 (1/4)		1	3	90									
	3	3 (3/8)	3 (3/8)		2	4	130									
	4	4 (1/2)	4 (1/2)		3	5	170									

▲选择“侧面孔数”中带【】的④、⑤规格时，Z不可选5 (M5)。

前后半贯通顶孔型  
MALBFP  
MALBFR  
(边长30×40-50×50)

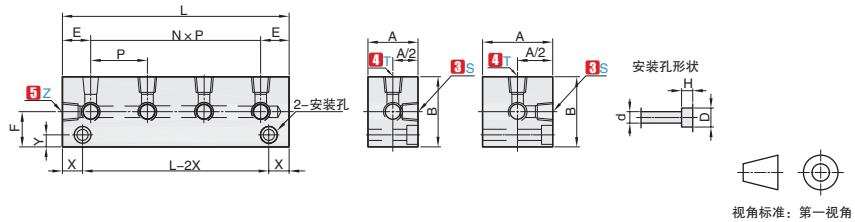

视角标准：第一视角



①代号 - ②侧面孔数K - ③S - ④T - ⑤Z  
MALAHEM - K3 - S1 - T1 - Z1

①代号	②侧面孔数K	RC(PT)/M选择		间距P	N	S·T·Z 螺孔数	L	A	B	E	F	X	Y	安装孔尺寸		
		③S	④T											⑤Z	d	D
前后半贯通 顶孔型 MALBFP (30×40)	1			30	0	2	40	30	40	20	20	7.5	7	5.5	9.5	6
	2	1 (1/8)	1 (1/8)		1	3	70									
	3	2 (1/4)	2 (1/4)		2	4	100									
	④	5 (M5)	5 (M5)		3	5	130									
	⑤				4	6	160									
前后半贯通 顶孔型 MALBFR (50×50)	1	1 (1/8)		40	0	2	50	50	50	25	25	8.5	8.5	8.5	14	9
	2	2 (1/4)	2 (1/4)		1	3	90									
	3	3 (3/8)	3 (3/8)		2	4	130									
	4	4 (1/2)	4 (1/2)		3	5	170									

▲选择“侧面孔数”中带【】的④、⑤规格时，Z不可选5 (M5)。