

# 梯形齿橡胶带

## H 型

成本  
经济型产品

交期缩短

大批量  
订购  
bulk order


■ H 型



型式	齿面保护层	材质	芯线
ABRN-H	尼龙帆布	氯丁橡胶	玻璃纤维

产品特点: 小型铣床、割草机、发电机、压缩机、碎边剪切机、钻孔整修机、钻孔机、玻璃制瓶机、食品机器、卷绳机、轧辊、木工机。

▲注: 使用温度 -20~80°C。

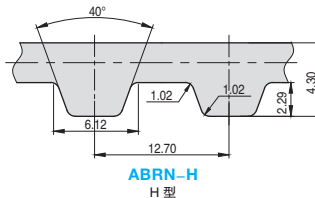

### 订购编号示例

① 代号	-	② 齿形	③ 公称宽度	-	④ 编号
ABRN	-	H	075	-	45

ABRN-H (齿距: 12.7mm)						ABRN-H (齿距: 12.7mm)					
① 代号	② 齿形	③ 公称宽度	④ 编号	周长 (mm)	齿数	① 代号	② 齿形	③ 公称宽度	④ 编号	周长 (mm)	齿数
ABRN	H	075 (19.1mm)	45	571.5	45	ABRN	H	075 (19.1mm)	170	2159	170
			46	584.2	46				172	2184.4	172
			48	609.6	48				176	2235.2	176
			49	622.3	49				180	2286	180
			54	685.8	54				190	2413	190
			56	711.2	56				200	2540	200
			60	762	60				220	2794	220
			62	787.4	62				226	2870.2	226
			63	800.1	63				250	3175	250
			64	812.8	64				265	3365.5	265
			66	838.2	66				270	3429	270
			68	863.6	68				280	3556	280
		70	889	70	340	4318	340				
		72	914.4	72							
		74	939.8	74							
		75	952.5	75							
		78	990.6	78							
		80	1016	80							
		82	1041.4	82							
		84	1066.8	84							
		86	1092.2	86							
		90	1143	90							
		93	1181.1	93							
		96	1219.2	96							
		98	1244.6	98							
		102	1295.4	102							
		106	1346.2	106							
		108	1371.6	108							
		112	1422.4	112							
		114	1447.8	114							
		120	1524	120							
		121	1536.7	121							
126	1600.2	126									
128	1625.6	128									
130	1651	130									
132	1676.4	132									
136	1727.2	136									
140	1778	140									
150	1905	150									
154	1955.8	154									
160	2032	160									
162	2057.4	162									
168	2133.6	168									
		100 (25.4mm)									
		150 (38.1mm)									
		200 (50.8mm)									

G5  
拉手/合页  
手柄/手轮  
门组件