




★ 产品特点：与高品质相比，性价比更高。




CAD
2D/3D

RoHS


标准加工

型式	齿面保护层	M材质	芯线
ABRN-H3M	尼龙帆布	氯丁橡胶	玻璃纤维

⚠ 使用温度-20~80°C。

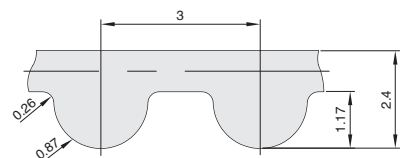

ABRN-H3M
H3M型

 

视角标准：第一视角



① 代号 - ② 齿形 ③ 公称宽度 - ④ 编号
 ABRN - H3M060 - 160

ABRN-H3M (齿距: 3mm)							
① 代号	② 齿形	③ 公称宽度	④ 编号	周长(mm)	齿数		
ABRN	H3M		111	111	37		
			114	114	38		
			117	117	39		
			120	120	40		
			123	123	41		
			126	126	42		
			129	129	43		
			132	132	44		
			135	135	45		
			138	138	46		
			141	141	47		
			144	144	48		
			147	147	49		
			150	150	50		
			153	153	51		
			156	156	52		
			159	159	53		
			162	162	54		
			165	165	55		
			168	168	56		
			171	171	57		
			174	174	58		
			177	177	59		
			060 (6mm)		180	180	60
					183	183	61
					186	186	62
				100 (10mm)	189	189	63
					192	192	64
					195	195	65
				150 (15mm)	198	198	66
					201	201	67
					204	204	68
					207	207	69
				210	210	70	
				213	213	71	
				216	216	72	
				219	219	73	
				222	222	74	
				225	225	75	
				228	228	76	
				231	231	77	
				234	234	78	
				237	237	79	
				240	240	80	
				243	243	81	
				246	246	82	
				249	249	83	
		252	252	84			
		255	255	85			
		258	258	86			
		261	261	87			
		264	264	88			
		267	267	89			

ABRN-H3M (齿距: 3mm)							
① 代号	② 齿形	③ 公称宽度	④ 编号	周长(mm)	齿数		
ABRN	H3M		270	270	90		
			273	273	91		
			276	276	92		
			279	279	93		
			282	282	94		
			285	285	95		
			288	288	96		
			291	291	97		
			294	294	98		
			297	297	99		
			300	300	100		
			303	303	101		
			306	306	102		
			309	309	103		
			312	312	104		
			315	315	105		
			318	318	106		
			321	321	107		
			324	324	108		
			327	327	109		
			330	330	110		
			333	333	111		
			336	336	112		
			060 (6mm)		339	339	113
					342	342	114
					345	345	115
				100 (10mm)	348	348	116
					351	351	117
					354	354	118
				150 (15mm)	357	357	119
					360	360	120
					363	363	121
					366	366	122
				369	369	123	
				372	372	124	
				375	375	125	
				378	378	126	
				381	381	127	
				384	384	128	
				387	387	129	
				390	390	130	
				393	393	131	
				396	396	132	
				399	399	133	
				402	402	134	
				405	405	135	
				408	408	136	
		411	411	137			
		414	414	138			
		417	417	139			
		420	420	140			
		423	423	141			
		426	426	142			

D4 同步带