

 

# 旋钮柱塞

F4  
弹簧柱塞

## ■ 嵌入式精密型



①代号	类型	螺纹	载荷	旋钮				主体				销			弹簧
				M	M	H	S	M	H	S	M	H	S	M	
JDACQC	嵌入式精密型	粗牙	轻载	尼龙6	S45C	33~38HRC	发黑	S45C	HV500-600	发黑	SUS304-WPB				
JDBCQC				SUS304	SUS304	-	-	SUS304	-	-					
JDACZC			重载	尼龙6	S45C	33~38HRC	发黑	S45C	HV500-600	发黑					
JDBCZC				SUS304	SUS304	-	-	SUS304	-	-					
JDADQC	自锁型	粗牙	轻载	尼龙6	S45C	33~38HRC	发黑	S45C	HV500-600	发黑	SUS304-WPB				
JDBDQC				SUS304	SUS304	-	-	SUS304	-	-					
JDADZC			重载	尼龙6	S45C	33~38HRC	发黑	S45C	HV500-600	发黑					
JDBDZC				SUS304	SUS304	-	-	SUS304	-	-					

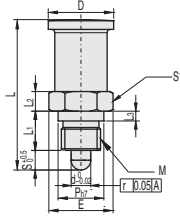

视角标准：第一视角



①代号 - ②M  
JDACQC - M10


①代号	②M	螺距(粗牙)	P <sub>n7</sub>	D	E	S	d	L	L <sub>1</sub>	L <sub>2</sub>	L <sub>3</sub>	S <sub>1</sub>	负载(N)				
													轻载		重载		
													min.	max.	min.	max.	
JDACQC	10	1.5	12	0 -0.018	18	16.2	5	5	38	10	5	3	14	4.5	7.3	5.7	11.9
JDBCQC	12	1.75	14		20	19.6	6	6	46	12	6		17	5.3	8.8	6.7	13.2
JDACZC	16	2	18	0 -0.021	26	25.4	8	8	56.5	16	10	4	22	5.7	10.1	7.4	17.2
JDBCZC													20	6.6	15	8	26.8

kgf=N×0.101972

## ■ 嵌入式精密型



①代号	类型	螺纹	载荷	旋钮				主体				销			弹簧
				M	M	H	S	M	H	S	M	H	S	M	
JDBCQX	嵌入式精密型	细牙	轻载	尼龙6	S45C	33~38HRC	发黑	S45C	HV500-600	发黑	SUS304-WPB				
JDACZX				SUS304	SUS304	-	-	SUS304	-	-					
JDBCZX			重载	尼龙6	S45C	33~38HRC	发黑	S45C	HV500-600	发黑					
JDADQX				SUS304	SUS304	-	-	SUS304	-	-					
JDBDQX	自锁型	细牙	轻载	尼龙6	S45C	33~38HRC	发黑	S45C	HV500-600	发黑	SUS304-WPB				
JDADZX				SUS304	SUS304	-	-	SUS304	-	-					
JDBDZX			重载	尼龙6	S45C	33~38HRC	发黑	S45C	HV500-600	发黑					
JDBDZX				SUS304	SUS304	-	-	SUS304	-	-					

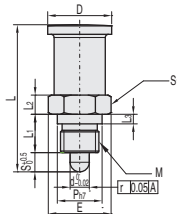

视角标准：第一视角



①代号 - ②M  
JDACQX - M10

①代号	②M	螺距(粗牙)	P <sub>n7</sub>	D	E	S	d	L	L <sub>1</sub>	L <sub>2</sub>	L <sub>3</sub>	S <sub>1</sub>	负载(N)				
													轻载		重载		
													min.	max.	min.	max.	
JDACQX	10	1	12	0 -0.018	18	16.2	5	5	38	10	5	3	14	4.5	7.3	5.7	11.9
JDBCQX	12	1.5	14		20	19.6	6	6	46	12	6		17	5.3	8.8	6.7	13.2
JDACZX	16	1.5	18	0 -0.021	26	25.4	8	8	56.5	16	10	4	22	5.7	10.1	7.4	17.2
JDBCZX													20	6.6	15	8	26.8