

 

旋钮柱塞

F4
弹簧柱塞

■ 嵌入式精密型



①代号	类型	螺纹	载荷	旋钮				主体				销			弹簧
				M	M	H	S	M	H	S	M	H	S	M	
JDACQC	嵌入式精密型	粗牙	轻载	尼龙6	S45C	33~38HRC	发黑	S45C	HV500-600	发黑	SUS304-WPB				
JDBCQC				SUS304	SUS304	-	-	SUS304	-	-					
JDACZC			尼龙6	S45C	33~38HRC	发黑	S45C	HV500-600	发黑						
JDBCZC			SUS304	SUS304	-	-	SUS304	-	-						
JDADQC	自锁型	粗牙	轻载	尼龙6	S45C	33~38HRC	发黑	S45C	HV500-600	发黑	SUS304-WPB				
JDBDQC				SUS304	SUS304	-	-	SUS304	-	-					
JDADZC			尼龙6	S45C	33~38HRC	发黑	S45C	HV500-600	发黑						
JDBDZC			SUS304	SUS304	-	-	SUS304	-	-						

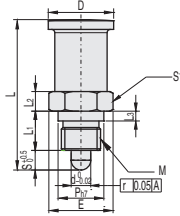

视角标准：第一视角



①代号 - ②M
JDACQC - M10



①代号	②M	螺距(粗牙)	P _{n7}	D	E	S	d	L	L ₁	L ₂	L ₃	S ₁	负载(N)				
													轻载		重载		
													min.	max.	min.	max.	
JDACQC	10	1.5	12	0 -0.018	18	16.2	5	5	38	10	5	3	14	4.5	7.3	5.7	11.9
JDBCQC	12	1.75	14		20	19.6	6	6	46	12	6		17	5.3	8.8	6.7	13.2
JDACZC	16	2	18	0 -0.021	26	25.4	8	8	56.5	16	10	4	22	5.7	10.1	7.4	17.2
JDBCZC													20	2.5	22	32	31.2

kgf=N×0.101972

■ 嵌入式精密型



①代号	类型	螺纹	载荷	旋钮				主体				销			弹簧
				M	M	H	S	M	H	S	M	H	S	M	
JDBCQX	嵌入式精密型	细牙	轻载	尼龙6	S45C	33~38HRC	发黑	S45C	HV500-600	发黑	SUS304-WPB				
JDACZX				SUS304	SUS304	-	-	SUS304	-	-					
JDBCZX			尼龙6	S45C	33~38HRC	发黑	S45C	HV500-600	发黑						
JDACZX			SUS304	SUS304	-	-	SUS304	-	-						
JDADQX	自锁型	细牙	轻载	尼龙6	S45C	33~38HRC	发黑	S45C	HV500-600	发黑	SUS304-WPB				
JDBDQX				SUS304	SUS304	-	-	SUS304	-	-					
JDADZX			尼龙6	S45C	33~38HRC	发黑	S45C	HV500-600	发黑						
JDBDZX			SUS304	SUS304	-	-	SUS304	-	-						

 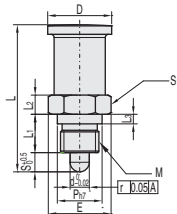

视角标准：第一视角



①代号 - ②M
JDACQX - M10

①代号	②M	螺距(粗牙)	P _{n7}	D	E	S	d	L	L ₁	L ₂	L ₃	S ₁	负载(N)				
													轻载		重载		
													min.	max.	min.	max.	
JDACQX	10	1	12	0 -0.018	18	16.2	5	5	38	10	5	3	14	4.5	7.3	5.7	11.9
JDBCQX	12	1.5	14		20	19.6	6	6	46	12	6		17	5.3	8.8	6.7	13.2
JDACZX	16	1.5	18	0 -0.021	26	25.4	8	8	56.5	16	10	4	22	5.7	10.1	7.4	17.2
JDBCZX													20	2.5	22	32	31.2