


锁紧销


■ 按钮平端型

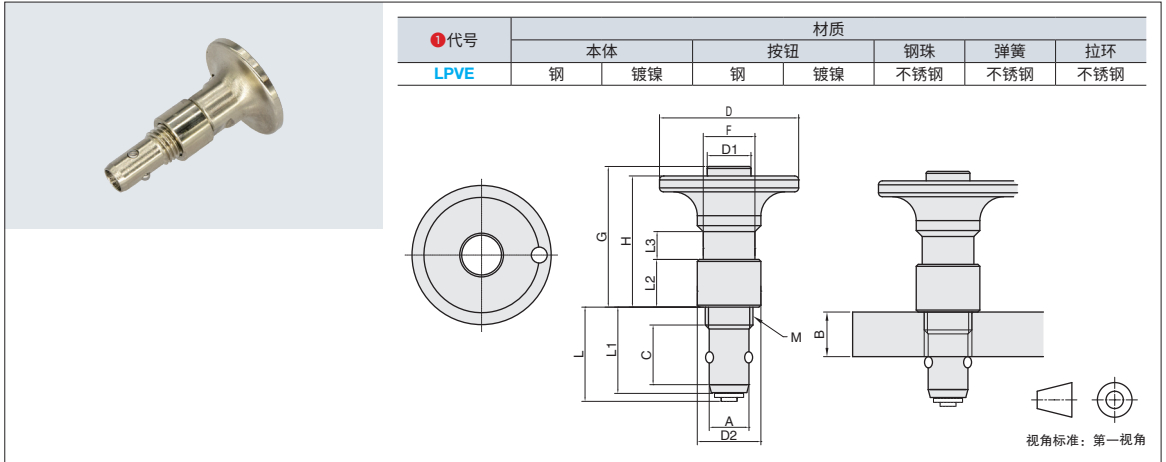

①代号 - ②A
LPVE - A6

①代号	②A ^{+0.023} _{+0.012}	M	适用板厚度B	C	D	D ₁	D ₂	L	L ₁	L ₂	L ₃	H	G	F
LPVE	6	M8×1.25	6~10	5.5	8	25	12	19	21	6	5.5	18	22	10
	8	M12×1.5	6~16	5.5	11	35	16	21.5	23.5	12	7	29	34.5	13

■ 按钮凸端型

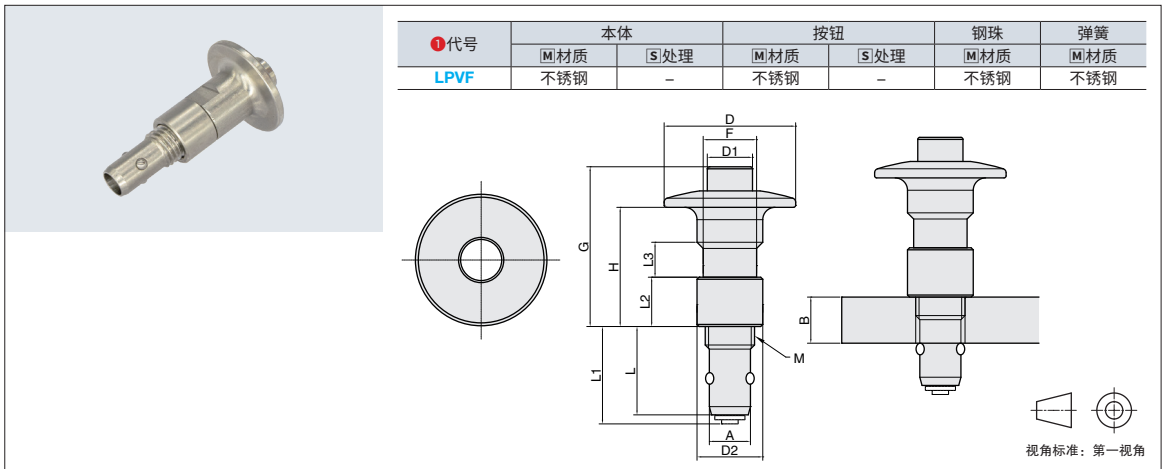

①代号 - ②A
LPVF - A6

①代号	②A ^{+0.023} _{+0.012}	M	适用板厚度B	C	D	D ₁	D ₂	L	L ₁	L ₂	L ₃	H	G	F
LPVF	6	M8×1.25	6~10	5.5	8	23	12	19	21	6	5.5	18	22	10
	10	M12×1.5	6~16	5.5	11	32	16	21.5	23.5	12	7	29	39.5	13