


锁紧销

■ 拉拔销



①代号	M材质					
	销	弹簧	把手	钢珠	按钮	环
LPVU	不锈钢	不锈钢	塑胶	不锈钢	不锈钢	不锈钢
LPVV			铝合金			

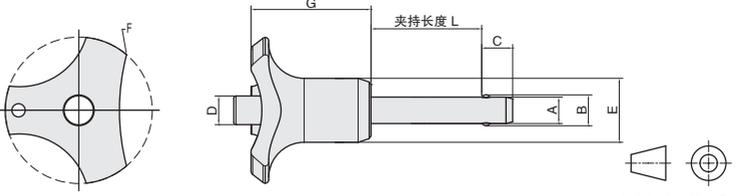

视角标准：第一视角




①代号 - ②A - ③L
LPVU - A5 - L20

①代号	②A -0.04 -0.08	夹持长度(选择) ③L +0.5 0	B	C	D	E	F	G
LPVU	5		5.5	7				
	6		7	7	6	16	38	31.5
	8	10 15 20 25 30	9.5	8				
	10	35 40 45 50 55	12	9				
	12	60 65 70 75 80	14.5	10	8	23	43	36
	14	85 90 95 100	16.5	11				
LPVV	16		19	14				
	20		24	19	15	34	57	50

■ 不锈钢主体拉拔销



①代号	M材质					
	销	弹簧	把手	钢珠	按钮	环
LPVW	不锈钢	不锈钢	铝合金	不锈钢	铝合金	不锈钢

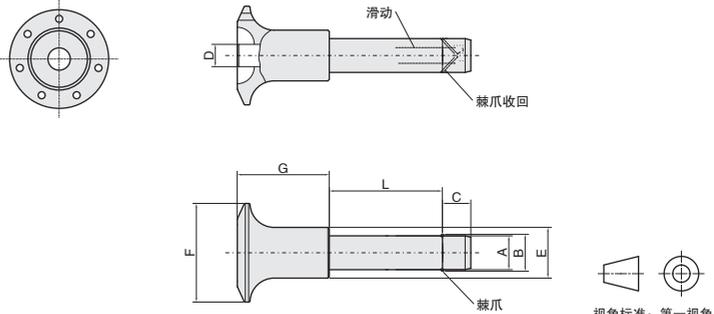

视角标准：第一视角



①代号 - ②A - ③L
LPVW - A5 - L20

①代号	②A -0.04 -0.08	夹持长度(选择) ③L +0.5 0	B	C	D	E	F	G
LPVW	6		8	7	6	16	30	24.5
	8		10.5	8.4	6	16	30	24.5
	10	10 15 20 25 30	13	9.8	7	18	35	32.5
	12	35 40 45 50 55	15	11.3	7	18	35	32.5
	16	60 65 70 75 80	20	14.2	7	22	40	33
	20		25	14.8	7	22	40	33