


内径E7外径r6

铜合金带肩标准型/薄壁型




★ 产品特点：可防止从板材上脱落的带肩规格。




①代号	类型	④材质	内径公差	外径公差	硬度 HB	使用温度范围 (°C)
OFAFZ	带肩标准型	高力黄铜+ 固体润滑剂GR1	E7	r6	≥210	-50~150
OFAFZU	带肩薄壁型	高力黄铜+ 固体润滑剂GR1	E7	r6	≥210	-50~150

▲ 配套轴(大气、油中使用)公差推荐(仅供参考): d8: 一般用(重载); e7-一般用(轻载);
 f8: 高精度用; g6: 高精度用(间隙负载)


▲ 基座孔推荐公差: H7

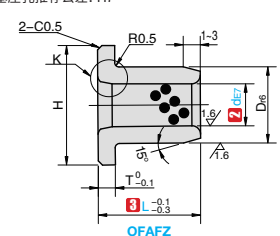


OFAFZ
带肩标准型

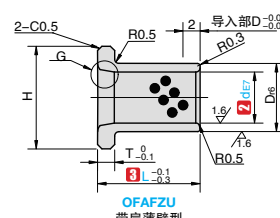

OFAFZU
带肩薄壁型

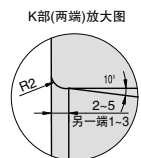

K部(两端)放大图

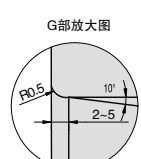

G部放大图

视角标准：第一视角



①代号 - ②d - ③L
OFAFZU - d20 - L20

型号		D _{r6}		③L					H	基座孔推荐公差	T				
①代号	②d _{E7}														
OFAFZ	5	+0.032	9	+0.028	10	12	15			14	+0.015	2			
	6	+0.020	10	+0.019	10	12	15	20		16	0				
	8	+0.040	12		10	12	15	20	25	20					
	10	+0.025	14	+0.034	10	12	15	20	25	30	35		+0.018		
	12		18	+0.023	10	12	15	20	25	30	35		0		
	13		19		10	12	15	20	25	30	35				
	15	+0.050	21		10	12	15	20	25	30	35				
	16	+0.032	22	+0.041		12	15	20	25	30	35	40	50	+0.021	
	18		24	+0.028			15	20	25	30	35	40	50	0	
	20		30			15	20	25	30	35	40	50			
	25	+0.061	35			15	20	25	30	35	40	50	60		
	30	+0.040	40	+0.050			20	25	30	35	40	50	60	50	+0.025
	35		45	+0.034			20	25	30	35	40	50	60	60	0
	40	+0.075	50				20	25	30	35	40	50	60	65	
	50	+0.050	60	+0.060					30	35	40	50	60	75	+0.030
			+0.041											0	

型号		D _{r6}		③L					H	基座孔推荐公差	T			
①代号	②d _{E7}													
OFAFZU	5	+0.032	7	+0.028	10	12	15			11	+0.015			
	6	+0.020	8	+0.019	10	12	15	20		12	0			
	8	+0.040	10		10	12	15	20		14				
	10	+0.025	12		10	12	15	20	25	30	16			
	12		15	+0.034	10	12	15	20	25	30	21	+0.018		
	13	+0.050	16	+0.023		12	15	20	25	30	22	0		
	15	+0.032	18		10	12	15	20	25	30	24			
	16		20			12	15	20	25	30	40	26	+0.021	
	20		24	+0.041			15	20	25	30	40	50	32	0
	25	+0.061	29	+0.028				20	25	30	40	50	37	
	30	+0.040	34	+0.050					25	30	40	50	42	+0.025
				+0.034										0



交货期

1天发货



优惠价

数量	1-9	10~
折扣率	100%	现询



百万商品齐上线, 获取专属企业折扣, 轻松下单



400-6699-428



www.ant-fa.com