





R型销/弹性销

★ 产品特点: 设计精细, 适用多种轴径

■ R型销

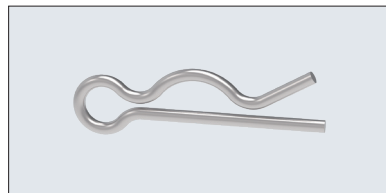

①代号	M材质	H硬度	S表面处理
RXJ	弹簧钢	40-50HRC	镀锌钝化
RXB	SUS304	-	-

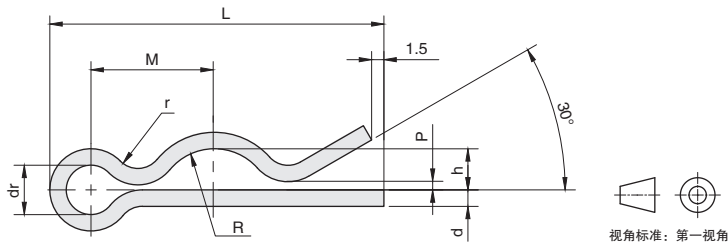

①代号 - ②D
RXJ - D4

订购编号示例

①代号	②D适用轴径	d	L	dr	M	R	h	r	P(max)
RXJ RXB	4	1	16.3	3	6	2	1	1.5	0.5
	5		17.9		6.5	2.5	1.5		
	6	1.2	21.2	3.6	7.8	3	1.8	1.8	0.6
	(7)		22.8		8.3	3.5	2.3		
	8	1.6	27.7	4.8	10.4	4	2.4	2.4	0.8
	(9)		29.3		10.9	4.5	2.9		
	10	1.8	32.6	5.4	12.2	5	3.2	2.7	0.9
	12		35.8		13.2	6	4.2		
	14	2	40.6	6	15	7	5	3	1
	16		43.8		16	8	6		

△ ()尺寸只适用材质RXB