 



固定调节型·带安装孔无橡胶垫



①代号	类型		S表面处理		M材质	
			螺杆	底座	螺杆	底座
SFBZMLK	固定调节型	圆形带橡胶垫	镀锌	镀铬	S45C	
SFBCMLK			镀铬			
SFSSLK			无	无	SUS304	

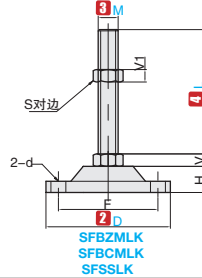

①代号 - ②D - ③M - ④L
SFSSLK - D80 - M20 - L100

G2 支脚

型号		③M	④L	S	H	H2	V	V1	F	d	承载 (Kg)	
①代号	②D											
SFBZMLK SFBCMLK SFSSLK	80	12	50	19	30	-	8	10	-	-	800	
			80									
			100									
			120									
			150									
			200									
	80	16	50	24	30	-	10	13	-	-	800	
			80									
			100									
			120									
			150									
			200									
	80	20	50	30	30	-	13	16	-	-	800	
			80									
			100									
			120									
			150									
			200									
	80	24	50	36	36	-	16	19	-	-	800	
			80									
			100									
			120									
			150									
			200									
100	12	12	50	19	28	16	8	10	80	12	1000	
			80									
			100									
			120									
			150									
			200									
	100	16	16	50	24	28	16	10	13	80	12	1000
				80								
				100								
				120								
				150								
				200								
100	20	20	50	30	28	16	13	16	80	12	1000	
			80									
			100									
			120									
			150									
			200									
100	24	24	50	36	28	16	16	19	80	12	1000	
			80									
			100									
			120									
			150									
			200									

分类目录



返回主目录

