




带挡边滚针轴承 标准型 开式 · 两侧带密封无内圈

★ 产品特点：主要用于转速较低的机件上

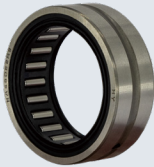

①代号	类型			轴承 ④材质	
				国标	相当
BLE	标准型	开式	两侧带密封 无内圈	GCr15	SUJ2

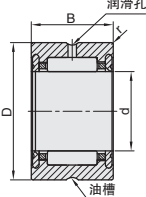

 





型号
BLE-RNA490DD

订购编号示例

①代号	②轴承型号	d	D	B	r min	基本额定负载		疲劳极限载荷 Cur N	极限转速 rpm	重量 (g)
						Cr(动) N	Cor(静) N			
BLE	RNA490DD	14	22	13	0.3	7700	6900	1360	13000	16
	RNA4901DD	16	24			8600	8300	1630	12000	18
	RNA4902DD	20	28			9700	10300	2040	10000	21.5
	RNA4903DD	22	30	17	0.6	10000	11000	2180	9000	23
	RNA4904DD	25	37			19500	19900	3750	7500	56
	RNA4905DD	30	42			21800	24200	4550	6500	60
	RNA4906DD	35	47			23900	28500	5400	5500	69
	RNA4907DD	42	55	22	0.6	29500	39500	7200	4800	107
	RNA4908DD	48	62			41000	53000	8800	4200	154
	RNA4909DD	52	68			43000	59000	9700	3900	157
RNA4910DD	58	72			45000	64000	10600	3500	160	

- ▲ 1kgf=9.8N
- ▲ 不承诺此产品品牌
- ▲ 更多规格请咨询客服



4天发货

C2
轴承-关节轴承-
锁紧螺母