



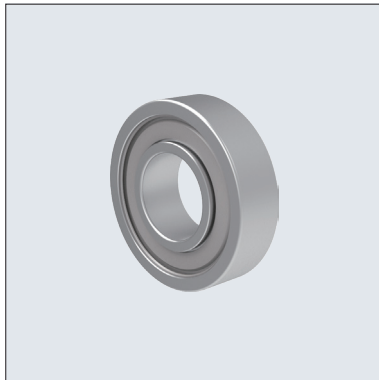

★ 产品特点：本产品适用于高精度、重载荷的场合，两侧的铁盖具有较好的防尘性

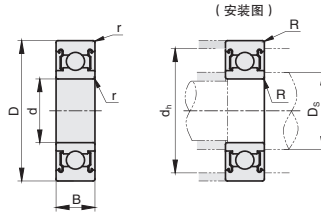

①代号	类型	后置代号	轴承④材质	
			GB	JIS
BRC	标准型	ZZ: 双面带防尘盖	GCr15	SUJ2
SBRC			2Gr13	SUS420
HQ-BRC	进口型		GCr15	SUJ2
HQ-SBRC			9Cr18Mo	SUS440C



视角标准：第一视角



型号
BRC-682ZZ

型号		d	D	B	r (min)	基本额定载荷				最大允许转速 (rpm)	安装尺寸			重量 g (参考)
①代号	②公称规格					标准型		进口型			D _s (min)	d _h (max)	R (max)	
		动载荷/N		静载荷/N		动载荷/N		静载荷/N						
BRC	682ZZ	2	5	2.3	0.08	143	40	169	50	85000	2.7	3.9	0.08	0.17
SBRC	692ZZ	2	6	3	0.15	281	79	330	98	75000	3	4.8	0.15	0.38
HQ-BRC	602ZZ	7	7	3.5	0.15	328	102	385	127	60000	3.2	5.8		0.58
HQ-SBRC	682AZZ	2.5	6	2.6	0.08	178	59	208	74	71000	3.7	4.9	0.08	0.29
	692AZZ	2.5	7	3.5	0.15	328	102	385	127	63000	3.85	5.65	0.15	0.55
	673ZZ		6	2.5	0.08	188	60	208	74	71000	3.6	5.4	0.08	0.2
	683ZZ		7	3	0.1	360	110	390	130	63000	3.9	5.8	0.1	0.45
	693ZZ		8	4		535	155	560	179	60000		6.8		0.61
	603ZZ	3	9	5	0.15	549	165	570	187	56000	4.2	7.8	0.15	1.13
	623ZZ		10	4		608	198	630	218	50000		8.8		1.6
	633ZZ		13	5	0.2	1270	455	1300	485	40000	4.6	11.4	0.2	3.43
	674ZZ		7	2.5	0.08	222	88	255	107	60000		6.4	0.08	0.28
	684ZZ		9			610	195	640	225	53000	5	7.8	0.1	1.01
	694ZZ		11	4	0.15	715	276	960	345		5.2	9.8	0.15	1.8
	604ZZ	4	12			930	305	960	345	48000		10.4		2.34
	624ZZ		13		0.2	1270	455	1300	485	40000	5.6	11.4	0.2	3.2
	634ZZ		16	5	0.3	1340	523	1730	670	36000	6	14	0.3	5.44
	675ZZ		8	2.5	0.1	218	101	278	131	53000	5.8	7.4	0.1	0.34
	685ZZ		11	5	0.15	665	251	715	281	45000	6.2	9.8		1.96
	695ZZ		13	4		1050	400	1080	430	43000		11.4	0.2	2.4
	605ZZ	5	14		0.2	1290	455	1330	505	40000	6.6	12.4		3.5
	625ZZ		16	5		1690	630	1730	670	36000	7	14	0.3	4.8
	635ZZ		19	6		2310	854	2340	885	32000		17		8.89
	676ZZ		10	3	0.1	465	198	495	218	45000	7.04	9.3	0.1	0.7
	686ZZ		13		0.16	1050	400	1080	440		7	11.8		2.69
	696ZZ		15	5	0.2	1350	530	1730	670	40000	7.6	13.4	0.2	3.8
	606ZZ	6	17			2190	800	2260	835	38000		15		6
	626ZZ		19	6	0.3	2300	855	2340	885	32000	8	17	0.3	8.1
	636ZZ		22	7		3100	1250	3300	1370	30000		20		14.5
	687ZZ		14	5	0.15	1130	465	1170	510	40000	8.2	12.8	0.15	2.97
	697ZZ		17	5		1565	682	1610	710			15		5.12
	607ZZ	7	19	6	0.3	2300	855	2340	885	36000	10.05	17	0.3	7.51
	627ZZ		22	7		3250	1310	3300	1370	30000		20		12.9
	678ZZ		12	3.5	0.1	515	254	545	274	40000	9.02	11.33	0.1	0.99
	688ZZ		16	5	0.2	1560	680	1610	710		9.6	14.4	0.2	4.02
	698ZZ		19	6		1990	865	2240	910	36000		17		7.3
	608ZZ	8	22	7		3250	1330	3300	1370	34000		20		12
	628ZZ		24	8	0.3	3315	1393	3350	1430		10	22	0.3	17
	638ZZ		28	9		4520	1940	4550	1970	28000		26		30.3
	689ZZ		17	4	0.2	1290	635	1330	665	33000	10.6	15.4	0.2	3.2
	699ZZ		20	6		1680	812	1720	840	32000		18		8.2
	609ZZ	9	24	7	0.3	3310	1400	3350	1430	31000	11	22	0.3	14
	629ZZ		26	8	0.6	4500	1960	4550	1970	30000	13	22		20

▲ 1kgf=9.8N
▲ 不承诺此产品品牌
▲ 更多规格请咨询客服



交货期

4天发货

C2 轴承类节轴承 / 锁紧螺母