


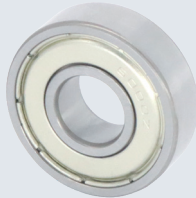


★ 产品特点：本产品适用于高精度、重载荷的场合C3游隙适于轴承内外温差较大的场合



①代号	类型	后置代号	轴承M材质	
			GB	JIS
BRH	标准型	C3: 大于普通游隙的一种	GCr15	SUJ2
HQ-BRH	进口型			

安装图

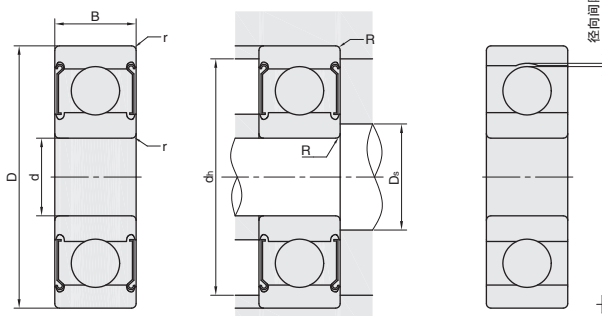

视角标准：第一视角



型号  
BRH-6200ZZC3

型号		d	D	B	r	基本额定载荷				容许转速 (rpm)	安装尺寸				重量 g (参考)
						标准型		进口型			D <sub>s</sub>		d <sub>h</sub> (max)	R (max)	
						动载荷/KN	静载荷/KN	动载荷/KN	静载荷/KN		(min)	(max)			
①代号	②公称规格	(min)													
	6000ZZC3	10	26	8	0.3	4.35	1.77	4.55	1.97	30000	12	13	24	0.3	18
	6200ZZC3		30	9	0.6	4.9	2.19	5.1	2.39	24000		16	26	0.6	32
	6300ZZC3		35	11		7.9	3.25	8.1	3.45	22000	14	16.5	31		52
	6001ZZC3		28	8	0.3	4.9	2.17	5.1	2.37	28000		15.5	26	0.3	22
	6201ZZC3	12	32	10	0.6	6.6	2.85	6.8	3.05	22000	16	17	28	0.6	37
	6301ZZC3		37	12	1	9.5	4	9.7	4.2	20000		18	32	1	60
	6002ZZC3		32	9	0.3	5.4	2.63	5.6	2.83	24000	17	19	30	0.3	31
	6202ZZC3	15	35	11	0.6	7.45	3.55	7.65	3.75	20000	19	20.5	31	0.6	45
	6302ZZC3		42	13	1	11.2	5.25	11.4	5.45	17000	20	22.5	37	1	83
	6003ZZC3		35	10	0.3	5.8	3.05	6	3.25	22000	19	21.5	33	0.3	41
	6203ZZC3	17	40	12	0.6	9.35	4.6	9.55	4.8	17000	21	23.5	36	0.6	67
	6303ZZC3		47	14	1	13.4	6.45	13.6	6.65	15000	22	25.5	42	1	113
	6004ZZC3		42	12	0.6	9.2	4.8	9.4	5	18000	24		38	0.6	68
	6204ZZC3	20	47	14	1	12.6	6.4	12.8	6.6	15000	25	26.5	42	1	107
	6304ZZC3		52	15	1.1	15.7	7.7	15.9	7.9	14000	26.5	28	45.5		145
	6005ZZC3		47	12	0.6	9.9	5.65	10.1	5.85	15000	29	30	43	0.6	79
	6205ZZC3	25	52	15	1	13.8	7.65	14	7.85	13000	30	32	47		129
	6305ZZC3		62	17	1.1	20.4	11	20.6	11.2	11000	31.5	36	55.5		235
	6006ZZC3		55	13		13	8.1	13.2	8.3	13000		36.5	50		116
	6206ZZC3	30	62	16	1	19.3	11.1	19.5	11.3	11000	35	38.5	57	1	199
	6306ZZC3		72	19	1.1	26.5	14.8	26.7	15	9500	36.5	42.5	65.5		345
	6007ZZC3		62	14	1	15.8	10.1	16	10.3	11000	40	41.5	57		151
	6207ZZC3	35	72	17	1.1	25.5	15.1	25.7	15.3	9500	41.5	44.5	65.5		284
	6307ZZC3		80	21	1.5	33.3	19	33.5	19.2	8500	43	47	72	1.5	464
	6008ZZC3		68	15	1	16.6	11.3	16.8	11.5	10000	45	47.5	63		190
	6208ZZC3	40	80	18	1.1	28.9	17.7	29.1	17.9	8500	46.5	50.5	73.5	1	366
	6308ZZC3		90	23	1.5	40.3	23.8	40.5	24	7500	48	53	82	1.5	636
	6009ZZC3		75	16	1	20.7	15	20.9	15.2	9000	50	53.5	70		241
	6209ZZC3	45	85	19	1.1	31.3	20.2	31.5	20.4	7500	51.5	55.5	78.5	1	420
	6309ZZC3		100	25	1.5	52.8	31.8	53	32	6700	53	61.5	92		829
	6010ZZC3		80	16	1	21.6	16.4	21.8	16.6	8500	55	58.5	75	2	261
	6210ZZC3	50	90	20	1.1	34.8	23	35	23.2	7100	56.5	60	83.5		459
	6310ZZC3		110	27	2	61.8	38.3	62	38.5	6000	59	68	101		1060

- ▲ 1kgf=9.8N
- ▲ 不承诺此产品品牌
- ▲ 更多规格请咨询客服



交货期

4天发货