

开式

标准型/进口型 深沟球轴承




产品特点：本产品适用于中低精度、轻载荷的场合

 


①代号	类型	轴承材质	
		GB	JIS
BRM BRD	标准型	GCr15	SUJ2
HQ-BRM HQ-BRD	进口型		

安装图

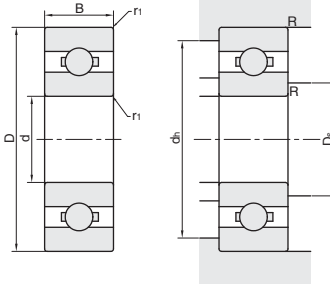

HQ-BRM适用于内径<10
HQ-BRD适用于内径≥10



型号
HQ-BRD-6801

①代号	②公称规格	d	D	B	r ₁ (min)	基本额定载荷				容许转速 rpm(参考)	安装尺寸			重量 g (参考)		
						标准		进口			D _s		d _h (max)		R (max)	
						动载荷/N	静载荷/N	动载荷/N	静载荷/N	(min)	(max)					
	683		7	2	0.1	311	112	390	130	63000	3.85		6.35	0.1	0.32	
	603	3	9	3	0.15	550	167	570	187	56000			7.9	0.15	0.84	
	623		10	4		611	199	630	218	50000	4.35		7.98		1.45	
	634	4	16		0.3	1340	523	1730	670	36000	6.7		13	0.3	5.24	
	605	5	14	5	0.2	1309	487	1330	505	40000	6.9		12.2	0.2	3.46	
	625		16			1710	650	1730	670	36000	7.5		13.8		4.95	
	606	6	17	6		2240	815	2260	835	38000	8.2		14.8		5.94	
	626		19		0.3	2310	855	2340	885	32000	8.5		16.5	0.3	8.12	
	608	8	22	7		3293	1340	3300	1370	34000	10.5		19.03		11.8	
	628		24	8		3333	1423	3350	1430	28000	11.9		19.9		17.1	
	6700		15	3	0.2	850	430	870	450	15000	10.4	11.21	14.2	0.2		
	6800		19	5		1690	810	1720	840	34000		12.5	17		5	
	6900	10	22	6	0.3	2670	1240	2700	1270	32000	12		13	20	0.3	9
	6000		26	8		4520	1940	4550	1970	30000		13.5	24		19	
	6200		30	9	0.6	5070	2360	5100	2390	24000	14		16	26	0.6	32
	6701		18	4	0.2	920	530	950	560	13000	12.4	13.86	16.7	0.2	3	
	6801		21	5		1890	1010	1920	1040	32000		14.5	19		6	
	6901	12	24	6	0.3	2860	1430	2890	1460	30000	14		15	22	0.3	11
	6001		28	8		5070	2340	5100	2370	28000		16	26		21	
	6201		32	10	0.6	6100	2750	6800	3050	22000	16		17	28	0.6	37
	6702		21	4	0.2	930	580	960	610	11000	15.4	16.86	19.7	0.2	4	
	6802		24	5		2040	1230	2070	1260	28000			22		7	
	6902	15	28	7	0.3	3650	2000	4350	2260	26000	17	17.5	26	0.3	16	
	6002		32	9		5570	2800	5600	2830	24000		19	30		30	
	6202		35	11	0.6	7620	3600	7650	3750	20000		20	31	0.6	45	
	6803		26	5		2230	1460	2630	1570	26000		19.5	24		8	
	6903	17	30	7	0.3	4570	2520	4600	2550	24000	19		20	28	0.3	18
	6003		35	10		5970	3220	6000	3250	22000		21	33		39	
	6203		40	12	0.6	9520	4600	9550	4800	17000	21		23	36	0.6	66
	6704		27	4	0.2	1400	720	1430	750	8500	20.4	22.36	25.5	0.2	6	
	6804		32	7		3960	2440	4000	2470	22000		22.5	30		19	
	6904	20	37	9	0.3	6370	3670	6400	3700	19000	22		24	35	0.3	36
	6004		42	12	0.6	9370	4970	9400	5000	18000		26	38	0.6	69	
	6204		47	14	1	12770	6570	12800	6600	15000	25		28	42	1	106
	6805		37	7		4300	2950	4500	3150	18000		28	35		22	
	6905	25	42	9	0.3	7020	4520	7050	4550	16000	27		29	40	0.3	42
	6005		47	12	0.6	10070	5820	10100	5850	15000	29	30.5	43	0.6	80	
	6205		52	15	1	13970	7820	14000	7850	13000	30		32	47	1	128
	6806		42	7		4670	3620	4700	3650	15000		33	40		26	
	6906	30	47	9	0.3	7220	4970	7250	5000	14000	32		34	45	0.3	48
	6006		55	13		13170	8270	13200	8300	13000		37	50		116	
	6206		62	16	1	19470	11270	19500	11300	11000	35		39	57	1	199
	6807		47	7	0.3	4870	4050	4900	4100	14000	37		38	45	0.3	29
	6907	35	55	10	0.6	9550	6850	10600	7250	12000	39		40	51	0.6	74
	6007		62	14	1	15970	10270	16000	10300	11000	40		42	57		155
	6207		72	17	1.1	25670	15270	25700	15300	9500	41.5		45	65.5	1	288
	6808		52	7	0.3	5100	4400	6350	5550	12000	42		43	50	0.3	33
	6908	40	62	12	0.6	12200	8900	13700	10000	11000	44		45	58	0.6	110
	6008		68	15	1	16770	11470	16800	11500	10000	45		47	63		190
	6208		80	18	1.1	29070	17800	29100	17900	8500	46.5		51	73.5		366
	6010	50	80	16	1	21800	16570	21770	16600	8500	55		57.5	75		261
	6210		90	20	1.1	34970	23170	35000	23200	7100	56.5		60	83.5		454

▲ 1kgf=9.8N

▲ 不承诺此产品品牌 ▲ 更多规格请咨询客服



交货期

4天发货

C2 轴承(关节轴承)
锁紧螺母