


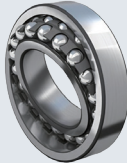


★ 产品特点: 在轴、外壳出现挠曲时, 可以自动调整, 不增加轴承负担




| ①代号 | 类型 | 后置代号 | 轴承④材质 | |
|--------|-----|--------------------|-------|------|
| | | | 国标 | 相当 |
| BSB | 标准型 | 无: 圆柱孔型 K: 圆锥孔型 | GCr15 | SUJ2 |
| BSC | | | | |
| HQ-BSB | 进口型 | | | |
| HQ-BSC | | | | |


圆柱形

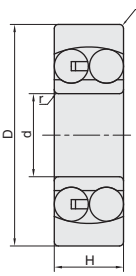


安装图

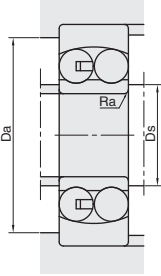


圆锥形

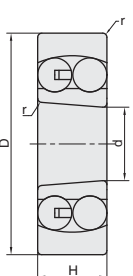

安装图

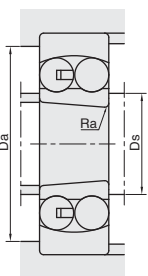

 

视角标准: 第一视角



型号
BSB-1207

| ①代号 | 型号 | | d | D | H | r (min) | 基本额定载荷 | | | | 极限转速(r/min) | | 安装尺寸 | | | 重量 Kg (参考) |
|-----|------|-------|----|-----|----|---------|--------|--------|--------|--------|-------------|-------|----------|----------|----------|------------------|
| | 圆柱孔型 | 圆锥孔型 | | | | | 标准型 | | 进口型 | | 脂润滑 | 油润滑 | Ds (min) | Da (max) | Ra (max) | |
| | | | | | | | 动载荷/KN | 静载荷/KN | 动载荷/KN | 静载荷/KN | | | | | | |
| | 1200 | - | 10 | 30 | 9 | | 5.06 | 0.99 | 5.5 | 1.19 | 24000 | 30000 | 14 | 26 | | 0.0336 |
| | 1201 | - | 12 | 32 | 10 | 0.6 | 5.58 | 1.07 | 5.7 | 1.27 | 22000 | 28000 | 16 | 28 | 0.6 | 0.0411 |
| | 1202 | - | 15 | 35 | 11 | | 7.47 | 1.55 | 7.6 | 1.75 | 19000 | 24000 | 19 | 31 | | 0.0497 |
| | 1302 | - | 15 | 42 | 13 | 1 | 9.52 | 2.09 | 9.7 | 2.29 | 17000 | 20000 | 20 | 37 | | 0.0966 |
| | 1303 | - | 17 | 47 | 14 | 0.6 | 11.8 | 3 | 12.7 | 3.2 | 14000 | 17000 | 22 | 42 | | 0.131 |
| | 1204 | 1204K | 20 | 52 | 15 | 1 | 9.8 | 2.41 | 10 | 2.61 | 15000 | 18000 | 25 | | | 0.116 |
| | 1205 | 1205K | 25 | 52 | 18 | 1 | 12 | 3.1 | 12.2 | 3.3 | 13000 | 16000 | 30 | 47 | | 0.139 |
| | 2205 | - | 25 | 52 | 18 | 1 | 12.2 | 3.25 | 12.4 | 3.45 | 11000 | 14000 | | | | 0.158 |
| | 1305 | - | 25 | 52 | 17 | 1.1 | 18 | 4.8 | 18.2 | 5 | 9500 | 12000 | 31.5 | 55.5 | 1 | 0.25 |
| | 1206 | 1206K | 30 | 62 | 16 | 1 | 15.6 | 4.45 | 15.8 | 4.65 | 10000 | 13000 | 35 | 57 | | 0.219 |
| | 2206 | - | 30 | 62 | 20 | 1 | 15.1 | 4.35 | 15.3 | 4.55 | 9500 | 12000 | | | | 0.25 |
| | 1207 | 1207K | 35 | 72 | 17 | | 15.7 | 4.9 | 15.9 | 5.1 | 9000 | 11000 | 41.5 | 65.5 | | 0.305 |
| | 2207 | - | 35 | 72 | 23 | | 21.5 | 6.4 | 21.7 | 6.6 | 8500 | 10000 | | | | 0.385 |
| | 1208 | - | 40 | 80 | 18 | 1.1 | 18.5 | 6.3 | 19.3 | 6.5 | | | 46.5 | 73.5 | | 0.393 |
| | 2208 | - | 40 | 80 | 23 | | 22.2 | 7.15 | 22.4 | 7.35 | 7500 | 9000 | | | | 0.488 |
| | 1308 | 1308K | 40 | 90 | 19 | | 29.6 | 9.5 | 29.8 | 9.7 | 6700 | 8000 | 48 | 82 | 1.5 | 0.673 |
| | - | 2308K | 40 | 90 | 33 | 1.5 | 45.3 | 13.3 | 45.5 | 13.5 | 6300 | 7500 | | | | 0.897 |
| | 1209 | 1209K | 45 | 85 | 19 | 1.1 | 21.7 | 7.15 | 22 | 7.35 | 7500 | 9000 | 51.5 | 78.5 | 1 | 0.47 |
| | 2209 | - | 45 | 85 | 23 | | 23.1 | 7.95 | 23.3 | 8.15 | 7000 | 8500 | 55.5 | | | 0.526 |
| | 1309 | 1309K | 45 | 100 | 25 | 1.5 | 38.3 | 12.5 | 38.5 | 12.7 | 6300 | 7500 | 53 | 92 | 1.5 | 0.932 |
| | 1210 | - | 50 | 90 | 20 | | 22.6 | 7.9 | 22.8 | 8.1 | 7000 | 8500 | 56.5 | 83.5 | 1 | 0.525 |
| | 2210 | - | 50 | 90 | 23 | 1.1 | 23.1 | 8.25 | 23.3 | 8.45 | 6300 | 7500 | | | | 0.559 |
| | 1310 | - | 50 | 110 | 27 | | 43.3 | 13.9 | 43.5 | 14.1 | 5600 | 6700 | 59 | 101 | 2 | 1.17 |
| | 2310 | - | 50 | 110 | 40 | 2 | 63.7 | 20 | 65 | 20.2 | 5300 | 6300 | | | | 1.65 |

- ▲ 1kgf=9.8N
- ▲ 不承诺此产品品牌
- ▲ 更多规格请咨询客服



交货期 **4**天发货

| | |
|-----|------|
| 数量 | 1~19 |
| 交货期 | 4工作日 |



爱安特自营商城焕新登场, 注册有礼, 一键直达



400-6699-428



www.ant-fa.com