




★ 产品特点: 主要用于转速较低的机件上



①代号	类型	轴承类型代码	轴承M材质	
			国标	相当
HQ-BTA	进口型	5	GCr15	SUJ2
BTA	标准型		2Gr13	SUS420
SBTA			0Cr18Ni9	SUS304
SBTA-.....-304				

(安装图)

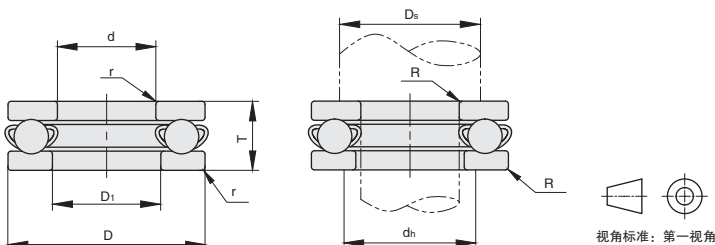

型号
BTA-51100

型号			d	d ₁ (max)	D ₁ (min)	D	T	r ₁ (min)	基本额定载荷(KN)		容许转速 rpm (参考)	d _a (min)	d _a (max)	r (max)	重量 kg (参考)
轴承材质 SUJ2	轴承材质 SUS420	轴承材质 SUS304							Cr(动)	Cor(静)					
BTA-51100	SBTA-51100	SBTA-51100-304	10	24	11	24	9	0.3	9.95	15.3	9500	19	15	0.3	0.02
BTA-51200	SBTA-51200	-	10	26	12	26	11	0.6	12.7	18.6	8000	20	16	0.6	0.03
BTA-51101	SBTA-51101	SBTA-51101-304	12	26	13	26	9	0.3	10.4	16.6	9000	21	17	0.3	0.02
BTA-51201	SBTA-51201	-	12	28	14	28	11	0.6	13.3	20.8	8000	22	18	0.6	0.03
BTA-51102	SBTA-51102	SBTA-51102-304	15	28	16	28	9	0.3	10.6	18.3	8500	23	20	0.3	0.02
BTA-51202	SBTA-51202	SBTA-51202-304	15	32	17	32	12	0.6	16.5	27	7000	25	22	0.6	0.05
BTA-51103	SBTA-51103	SBTA-51103-304	17	30	18	30	9	0.3	11.4	21.2	8500	25	22	0.3	0.03
BTA-51203	SBTA-51203	SBTA-51203-304	17	35	19	35	12	0.6	17.2	30	6700	28	24	0.6	0.05
BTA-51104	SBTA-51104	SBTA-51104-304	20	35	21	35	10	0.3	15.1	29	7500	29	26	0.3	0.04
BTA-51204	SBTA-51204	SBTA-51204-304	20	40	22	40	14		22.5	40.5	6000	32	28		0.08
BTA-51105	SBTA-51105	SBTA-51105-304	25	42	26	42	11	0.6	18.2	39	6300	35	32	0.6	0.06
BTA-51205	SBTA-51205	SBTA-51205-304	25	47	27	47	15		27.6	55	5300	38	34		0.11
BTA-51305	SBTA-51305	-	25	52	27	52	18		34.5	60	4500	41	36		0.17
BTA-51405	-	-	25	60		60	24	1	55.3	96.5	3600	46	39	1	0.34
BTA-51106	SBTA-51106	SBTA-51106-304	30	47		47	11	0.6	19	43	6000	40	37	0.6	0.06
BTA-51206	SBTA-51206	SBTA-51206-304	30	52	32	52	16		25.5	51	4800	43	39		0.13
BTA-51306	SBTA-51306	-	30	60	21	60	21	1	37.7	71	3800	48	42	1	0.26
BTA-51406	-	-	30	70		70	28	1	72.8	137	3000	54	46		0.52
BTA-51107	SBTA-51107	SBTA-51107-304	35	52		52	12	0.6	19.9	51	5600	45	42	0.6	0.08
BTA-51207	SBTA-51207	SBTA-51207-304	35	62		62	18		35.1	73.5	4000	51	46		0.22
BTA-51307	SBTA-51307	-	35	68	37	68	24	1	49.4	96.5	3200	55	48	1	0.39
BTA-51407	-	-	35	80		80	32	1.1	87.1	170	2600	62	53		0.79
BTA-51108	SBTA-51108	SBTA-51108-304	40	60		60	13	0.6	26	63	5000	52	48	0.6	0.12
BTA-51208	SBTA-51208	SBTA-51208-304	40	68	42	68	19		46.8	106	3800	57	51		0.28
BTA-51308	SBTA-51308	-	40	78		78	26	1	61.8	122	3000	63	55	1	0.53
BTA-51408	-	-	40	90		90	36	1.1	112	224	2400	70	60		1.1
BTA-51109	SBTA-51109	SBTA-51109-304	45	65		65	14	0.6	26.5	69.5	4500	57	53	0.6	0.14
BTA-51209	SBTA-51209	-	45	73	47	73	20		39	86.5	3600	62	56		0.3
BTA-51309	-	-	45	85		85	28	1	76.1	153	2800	69	61	1	0.66
BTA-51409	-	-	45	100		100	39	1.1	130	265	2200	78	67		1.4
BTA-51110	SBTA-51110	SBTA-51110-304	50	70		70	14	0.6	27	75	4300	62	58	0.6	0.16
BTA-51210	SBTA-51210	-	50	78	52	78	22	1	49.4	116	3400	67	61	1	0.37

▲ 1kgf=9.8N

▲ 不承诺此产品品牌

▲ 止推圈在交货时可能有少许变形, 使用前请以同心圆的方式施加200N以上的轴向载荷使之平整

▲ 止推圈和保持架是可拆解的, 使用时请注意

▲ 亦可提供双向推力球轴承

▲ 更多规格请咨询客服



交货期

4天发货

C2 轴承类节轴承
锁紧螺母