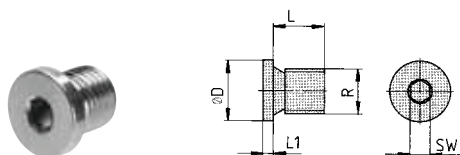


DIN 908
Tampão roscado, zincado

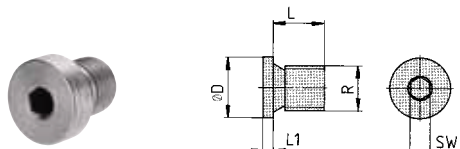

CAD



Nº enc.	Nº do artigo	R	L	L1	ØD	SW	máx. de funcionamento [bar]	Peso [g]
69393	908-G1/8	G1/8	8	3	14	5	400	6
69419	908-G1/4	G1/4	12	3	18	6	400	13
176701	908-G3/8*	G3/8	12	5	24	8	400	22
179952	908-M16x1,5*	M16x1,5	12	5	22	8	400	24

Nº 908S
Parafuso de purga, zincado


CAD



Nº enc.	Nº do artigo	R	L	L1	ØD	SW	máx. de funcionamento [bar]	Peso [g]
326389	908S-G1/8*	G1/8	8	4	14	5	400	6
343632	908S-G1/4*	G1/4	12	5	19	6	400	17

DIN 7603
Anel de vedação Cobre, forma A


CAD



Nº enc.	Nº do artigo	L	ØD	ØD1	máx. de funcionamento [bar]	Peso [g]
69815	7603-Form A-G1/8	1,0	13,5	10,0	400	0,5
69823	7603-Form A-G1/4	1,5	18,0	13,5	400	1,0

Exemplo de montagem:

- 1) Cilindro de pistões ocios N° 6920
- 2) Anel de vedação DIN 7603A
- 3) Bocal roscado N° 6993
- 4) Mangueira de alta pressão N° 6985
- 5) Engate rápido macho N° 6990-G1/4S
- 6) Engate rápido fêmea N° 6990-G1/4M



CAD