


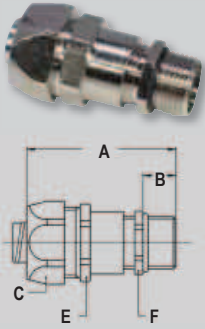


Raccordo-pressacavo Pg in ottone nichelato



| Filetto Pg | Sealtite Ø (inch) | Ø cavo min-max (mm) | Dimensioni in mm | | | | | Confezione standard | Codice articolo | Peso (Kg/100) |
|---------------|----------------------|------------------------|------------------|----|----|----|----|------------------------|--------------------|------------------|
| | | | A | B | C | E | F | | | |
| Pg 9 | 5/16" | 4 - 8 | 55 | 10 | 26 | 24 | 17 | 25 | 810.709.1 | 7,8 |
| Pg 9 | 3/8" | 5 - 8 | 55 | 10 | 26 | 24 | 20 | 25 | 810.712.1 | 7,8 |
| Pg 11 | 3/8" | 5 - 10 | 55 | 10 | 26 | 24 | 20 | 25 | 810.711.1 | 9,5 |
| Pg 13,5 | 1/2" | 6 - 12 | 57 | 10 | 29 | 27 | 22 | 25 | 810.715.1 | 9,7 |
| Pg 16 | 1/2" | 10 - 13,9 | 60 | 10 | 29 | 27 | 24 | 25 | 810.716.1 | 11,7 |
| Pg 21 | 3/4" | 13 - 18 | 67 | 12 | 35 | 33 | 30 | 25 | 810.721.1 | 19,6 |
| Pg 29 | 1" | 18 - 23,8 | 80 | 12 | 45 | 43 | 40 | 10 | 810.729.1 | 35,4 |




Raccordo-pressacavo EMC, Pg in ottone nichelato

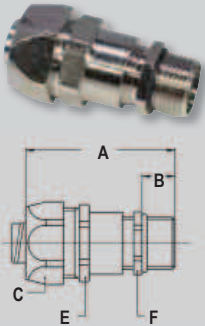

| Filetto Pg | Sealtite Ø (inch) | Ø cavo min-max (mm) | Dimensioni in mm | | | | | Confezione standard | Codice articolo | Peso (Kg/100) |
|---------------|----------------------|------------------------|------------------|----|----|----|----|------------------------|--------------------|------------------|
| | | | A | B | C | E | F | | | |
| Pg 9 | 5/16" | 4 - 8 | 55 | 10 | 26 | 24 | 17 | 25 | 810.609.1 | 7,8 |
| Pg 9 | 3/8" | 5 - 8 | 55 | 10 | 26 | 24 | 20 | 25 | 810.612.1 | 7,8 |
| Pg 11 | 3/8" | 5 - 10 | 55 | 10 | 26 | 24 | 20 | 25 | 810.611.1 | 9,5 |
| Pg 13,5 | 1/2" | 6 - 12 | 57 | 10 | 29 | 27 | 22 | 25 | 810.615.1 | 9,7 |
| Pg 16 | 1/2" | 10 - 13,9 | 60 | 10 | 29 | 27 | 24 | 25 | 810.616.1 | 11,7 |
| Pg 21 | 3/4" | 13 - 18 | 67 | 12 | 35 | 33 | 30 | 25 | 810.621.1 | 19,6 |
| Pg 29 | 1" | 18 - 23,8 | 80 | 12 | 45 | 43 | 40 | 10 | 810.629.1 | 35,4 |



Raccordo NPT maschio diretto in ottone nichelato

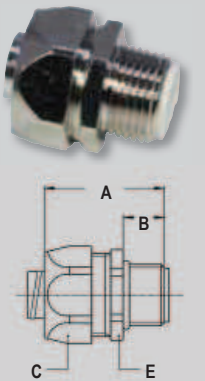


| Filetto NPT | Sealtite Ø (inch) | Passaggio utile (mm) | Dimensioni in mm | | | | | Confezione standard | Codice articolo | Peso (Kg/100) |
|----------------|----------------------|-------------------------|------------------|----|-----|---|-----|------------------------|--------------------|------------------|
| | | | A | B | C | D | E | | | |
| 1/2" NPT | 5/16" | 8,3 | 35 | 12 | 26 | - | 24 | 50 | 814.011.1* | 5,6 |
| 1/2" NPT | 3/8" | 10,2 | 35 | 12 | 26 | - | 24 | 50 | 814.012.1 | 5,6 |
| 1/2" NPT | 1/2" | 13,9 | 37 | 13 | 29 | - | 27 | 50 | 814.016.1 | 6,2 |
| 3/4" NPT | 3/4" | 18,5 | 40 | 15 | 35 | - | 33 | 25 | 814.020.1 | 8,9 |
| 1" NPT | 1" | 23,8 | 46 | 15 | 45 | - | 43 | 10 | 814.026.1 | 25,0 |
| 1.1/4" NPT | 1.1/4" | 31,8 | 52 | 16 | 54 | - | 52 | 5 | 814.035.1 | 40,0 |
| 1.1/2" NPT | 1.1/2" | 36,8 | 56 | 18 | 63 | - | 60 | 5 | 814.040.1 | 43,8 |
| 2" NPT | 2" | 47,8 | 66 | 20 | 77 | - | 74 | 4 | 814.050.1 | 73,5 |
| 2.1/2" NPT | 2.1/2" | 59,0 | 72 | 24 | 95 | - | 90 | 4 | 814.063.1* | 134,4 |
| 3" NPT | 3" | 71,5 | 80 | 28 | 110 | - | 105 | 2 | 814.075.1* | 172,8 |
| 4" NPT | 4" | 96,0 | 92 | 32 | 145 | - | 135 | 2 | 814.099.1* | 300,0 |

*Raccordi per guaine con diametro 1/4", 5/16", 2.1/2", 3" e 4" sono privi di omologazioni UL/CSA.



Raccordo NPT femmina diretto in ottone nichelato

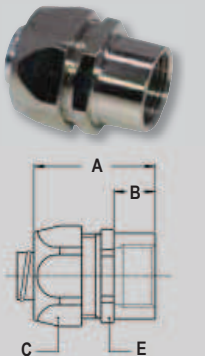

| Filetto NPT | Sealtite Ø (inch) | Passaggio utile (mm) | Dimensioni in mm | | | | | Confezione standard | Codice articolo | Peso (Kg/100) |
|----------------|----------------------|-------------------------|------------------|----|----|---|----|------------------------|--------------------|------------------|
| | | | A | B | C | D | E | | | |
| 1/2" NPT | 5/16" | 8,3 | 37 | 13 | 26 | - | 24 | 50 | 814.311.1* | 5,3 |
| 1/2" NPT | 3/8" | 10,2 | 37 | 13 | 26 | - | 24 | 50 | 814.312.1 | 5,3 |
| 1/2" NPT | 1/2" | 13,9 | 37 | 13 | 29 | - | 27 | 50 | 814.316.1 | 6,2 |
| 3/4" NPT | 3/4" | 18,5 | 40 | 15 | 35 | - | 33 | 25 | 814.320.1 | 9,0 |
| 1" NPT | 1" | 23,8 | 46 | 15 | 45 | - | 43 | 10 | 814.326.1 | 20,7 |
| 1.1/4" NPT | 1.1/4" | 31,8 | 52 | 16 | 54 | - | 52 | 5 | 814.335.1 | 29,3 |
| 1.1/2" NPT | 1.1/2" | 36,8 | 56 | 18 | 63 | - | 60 | 5 | 814.340.1 | 43,8 |
| 2" NPT | 2" | 47,8 | 66 | 20 | 77 | - | 74 | 4 | 814.350.1 | 73,3 |

* Raccordi per guaine con diametro 5/16" sono privi di omologazione UL/CSA.

RACCORDI
ANACONDA

RACCORDI
A TENUTA
STAGNA IP 67
PER SEALTITE