

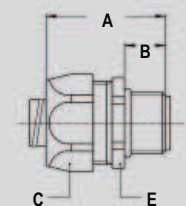


### Raccord mâle droit NPT en acier inoxydable AISI-303 (kit de raccordement inclus)

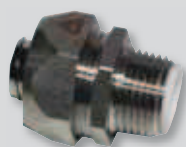

Filetage	UI (Pouce)	Diam. intérieur Min. (mm)	Dimensions en mm					Condition. Standard	Référence Article	Poids (Kg/100)
			A	B	C	D	E			
1/2" NPT	5/16"	6,8	35	12	27	-	24	10	814.011.8	7,4
1/2" NPT	3/8"	9,8	35	12	27	-	24	10	814.012.8	7,6
1/2" NPT	1/2"	13,9	37	13	30	-	27	10	814.016.8	8,5
3/4" NPT	3/4"	18,5	40	15	36	-	36	5	814.020.8	12,6
1" NPT	1"	22,8	46	15	46	-	46	5	814.026.8	29,6

### Raccord mâle 90° NPT en acier inoxydable AISI-303 (kit de raccordement inclus)

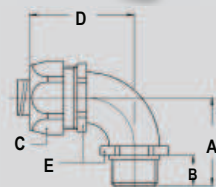

Filetage	UI (Pouce)	Diam. intérieur Min. (mm)	Dimensions en mm					Condition. Standard	Référence Article	Poids (Kg/100)
			A	B	C	D	E			
1/2" NPT	5/16"	6,8	32	12	27	42	22	10	814.911.8	15,8
1/2" NPT	3/8"	9,8	32	12	27	42	22	10	814.912.8	16,0
1/2" NPT	1/2"	13,9	36	13	30	43	27	10	814.916.8	17,6
3/4" NPT	3/4"	18,5	43	15	36	48	33	5	814.920.8	26,8
1" NPT	1"	22,8	48	15	46	59	42	5	814.926.8	36,8

ANACONDA  
MULTIFLEX

RACCORDS  
POUR GAINÉ  
UI  
IP 40