



**NPT gerade Verschraubung, Aussengewinde, Edelstahl
AISI-303 (einschl. Einschraubset).**

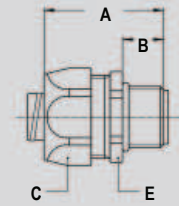

| Gewinde | UI | Min. Innen Durchm. (mm) | Abmessungen in mm | | | | | Standard Verpackung | Artikel Nummer | Gewicht (Kg/100) |
|----------|-------|----------------------------|-------------------|----|----|---|----|------------------------|-------------------|---------------------|
| | | | A | B | C | D | E | | | |
| 1/2" NPT | 5/16" | 6,8 | 35 | 12 | 27 | - | 24 | 10 | 814.011.8 | 7,4 |
| 1/2" NPT | 3/8" | 9,8 | 35 | 12 | 27 | - | 24 | 10 | 814.012.8 | 7,6 |
| 1/2" NPT | 1/2" | 13,9 | 37 | 13 | 30 | - | 27 | 10 | 814.016.8 | 8,5 |
| 3/4" NPT | 3/4" | 18,5 | 40 | 15 | 36 | - | 36 | 5 | 814.020.8 | 12,6 |
| 1" NPT | 1" | 22,8 | 46 | 15 | 46 | - | 46 | 5 | 814.026.8 | 29,6 |

**NPT 90° Winkel Verschraubung, Aussengewinde,
Edelstahl AISI-303 (einschl. Einschraubset).**

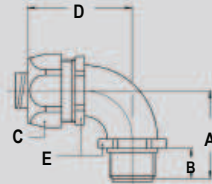

| Gewinde | UI | Min. Innen Durchm. (mm) | Abmessungen in mm | | | | | Standard Verpackung | Artikel Nummer | Gewicht (Kg/100) |
|----------|-------|----------------------------|-------------------|----|----|----|----|------------------------|-------------------|---------------------|
| | | | A | B | C | D | E | | | |
| 1/2" NPT | 5/16" | 6,8 | 32 | 12 | 27 | 42 | 22 | 10 | 814.911.8 | 15,8 |
| 1/2" NPT | 3/8" | 9,8 | 32 | 12 | 27 | 42 | 22 | 10 | 814.912.8 | 16,0 |
| 1/2" NPT | 1/2" | 13,9 | 36 | 13 | 30 | 43 | 27 | 10 | 814.916.8 | 17,6 |
| 3/4" NPT | 3/4" | 18,5 | 43 | 15 | 36 | 48 | 33 | 5 | 814.920.8 | 26,8 |
| 1" NPT | 1" | 22,8 | 48 | 15 | 46 | 59 | 42 | 5 | 814.926.8 | 36,8 |

**ANACONDA
MULTIFLEX**

**VERSCHRAU-
BUNGEN FÜR
TYP UI
IP 40**