



ISO 90° Winkel Verschraubung, Aussengewinde, Edelstahl AISI-303 (einschl. Einschraubset).

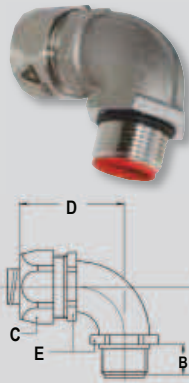


Gewinde	UI	Min. Innen Durchm. (mm)	Abmessungen in mm					Standard Verpackung	Artikel Nummer	Gewicht (Kg/100)
			A	B	C	D	E			
M16 x 1,5	5/16"	6,8	32	12	27	42	22	10	812.915.8	10,3
M20 x 1,5	5/16"	6,8	33	13	27	42	22	10	812.914.8	10,4
M16 x 1,5	3/8"	9,8	32	12	27	42	22	10	812.916.8	10,5
M20 x 1,5	3/8"	9,8	33	13	27	42	22	10	812.917.8	10,7
M20 x 1,5	1/2"	13,9	36	13	30	43	27	10	812.920.8	15,4
M25 x 1,5	3/4"	18,5	43	15	36	48	33	5	812.925.8	23,7

ISO gerade Kabel-Schlauch-Verschraubung, Aussengewinde, Edelstahl AISI-303 (einschl. Einschraubset).

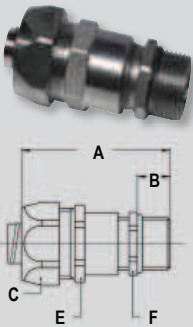


Thread	UI	Clamping Range (mm)	Dimensions in mm					Standard Package	Article Number	Weight (Kg/100)
			A	B	C	E	F			
M16 x 1,5	5/16"	4 - 6,8	57	12	27	24	18	10	812.715.8	7,9
M16 x 1,5	3/8"	4 - 8	57	12	27	24	18	10	812.716.8	10,0
M20 x 1,5	3/8"	6 - 9,8	57	12	27	24	22	10	812.717.8	11,9
M20 x 1,5	1/2"	6 - 12	59	12	30	27	22	10	812.720.8	12,3

Pg gerade Verschraubung, Aussengewinde, Edelstahl AISI-303 (einschl. Einschraubset).

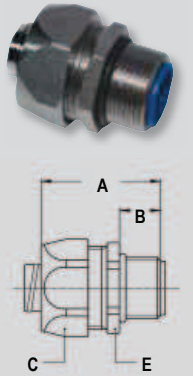

Gewinde	UI	Min. Innen Durchm. (mm)	Abmessungen in mm					Standard Verpackung	Artikel Nummer	Gewicht (Kg/100)
			A	B	C	D	E			
Pg 11	5/16"	6,8	35	12	27	-	24	10	810.012.8	7,6
Pg 11	3/8"	9,8	35	12	27	-	24	10	810.011.8	7,4
Pg 13,5	5/16"	6,8	35	12	27	-	24	10	810.014.8	7,6
Pg 13,5	3/8"	9,8	35	12	27	-	24	10	810.013.8	7,4
Pg 16	1/2"	13,9	37	13	30	-	27	10	810.016.8	8,6
Pg 21	3/4"	18,5	40	15	36	-	36	5	810.021.8	12,1
Pg 29	1"	22,8	46	15	46	-	46	5	810.029.8	29,6
Pg 36	1.1/4"	30,8	52	16	54	-	52	2	810.036.8	41,1
Pg 42	1.1/2"	36,8	56	18	63	-	60	2	810.042.8	55,0
Pg 48	2"	47,8	66	20	77	-	74	2	810.048.8	87,8

Pg 90° Winkel Verschraubung, Aussengewinde, Edelstahl AISI-303 (einschl. Einschraubset).

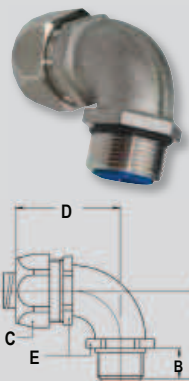

Gewinde	UI	Min. Innen Durchm. (mm)	Abmessungen in mm					Standard Verpackung	Artikel Nummer	Gewicht (Kg/100)
			A	B	C	D	E			
Pg 11	5/16"	6,8	32	12	27	42	22	10	810.912.8	11,2
Pg 11	3/8"	9,8	32	12	27	42	22	10	810.911.8	11,0
Pg 16	1/2"	13,9	36	13	30	43	27	10	810.916.8	18,3
Pg 21	3/4"	18,5	43	15	36	48	33	5	810.921.8	26,3
Pg 29	1"	22,8	48	15	46	59	42	5	810.929.8	40,7

ANACONDA
MULTIFLEX

VERSCHRAUBUNGEN FÜR
TYP UI
IP 40