



**NPT gerade Verschraubung, Aussengewinde, Messing-vernickelt (einschl. Einschraubset).**

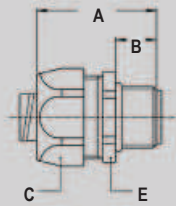


Gewinde NPT	UIG / UI NW (Zoll)	Min. Innen Durchm. (mm)	Abmessungen in mm					Standard Verpackung	Artikel Nummer	Gewicht (Kg/100)
			A	B	C	D	E			
1/2" NPT	5/16"	6,8	35	12	26	-	24	50	814.011.7	7,0
1/2" NPT	3/8"	9,8	35	12	26	-	24	50	814.012.7	7,2
1/2" NPT	1/2"	13,9	37	13	29	-	27	50	814.016.7	8,0
3/4" NPT	3/4"	18,5	40	15	35	-	33	25	814.020.7	11,9
1" NPT	1"	22,8	46	15	45	-	43	10	814.026.7	27,6
1.1/4" NPT	1.1/4"	30,8	52	16	54	-	52	5	814.035.7	43,8
1.1/2" NPT	1.1/2"	36,8	56	18	63	-	60	5	814.040.7	49,4
2" NPT	2"	47,8	66	20	77	-	74	4	814.050.7	82,9

**NPT gerade Verschraubung, Innengewinde, Messing-vernickelt (einschl. Einschraubset).**

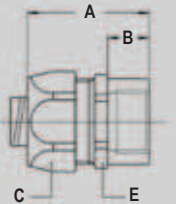


Gewinde NPT	UIG / UI NW (Zoll)	Min. Innen Durchm. (mm)	Abmessungen in mm					Standard Verpackung	Artikel Nummer	Gewicht (Kg/100)
			A	B	C	D	E			
1/2" NPT	5/16"	6,8	37	13	26	-	24	50	814.311.7	6,7
1/2" NPT	3/8"	9,8	37	13	26	-	24	50	814.312.7	6,9
1/2" NPT	1/2"	13,9	37	13	29	-	27	50	814.316.7	8,0
3/4" NPT	3/4"	18,5	40	15	35	-	33	25	814.320.7	12,0
1" NPT	1"	22,8	46	15	45	-	43	10	814.326.7	23,3
1.1/4" NPT	1.1/4"	30,8	52	16	54	-	52	5	814.335.7	33,1
1.1/2" NPT	1.1/2"	36,8	56	18	63	-	60	5	814.340.7	49,4
2" NPT	2"	47,8	66	20	77	-	74	4	814.350.7	82,7

**NPT 90° Winkel Verschraubung, Aussengewinde, Messing-vernickelt (einschl. Einschraubset).**

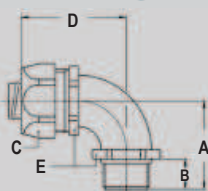

Gewinde NPT	UIG / UI NW (Zoll)	Min. Innen Durchm. (mm)	Abmessungen in mm					Standard Verpackung	Artikel Nummer	Gewicht (Kg/100)
			A	B	C	D	E			
1/2" NPT	5/16"	6,8	32	12	26	42	22	50	814.911.7	14,7
1/2" NPT	3/8"	9,8	32	12	26	42	22	50	814.912.7	14,9
1/2" NPT	1/2"	13,9	36	13	29	43	27	50	814.916.7	16,4
3/4" NPT	3/4"	18,5	43	15	35	48	33	25	814.920.7	25,0
1" NPT	1"	22,8	48	15	45	59	42	10	814.926.7	34,3
1.1/4" NPT	1.1/4"	30,8	57	16	54	68	51	5	814.935.7	66,3
1.1/2" NPT	1.1/2"	36,8	63	18	63	78	60	5	814.940.7	94,7
2" NPT	2"	47,8	74	20	77	96	74	4	814.950.7	151,3

**NPT gerade Kabel-Schlauch-Verschraubung, Aussengewinde, Messing-vernickelt (einschl. Einschraubset).**

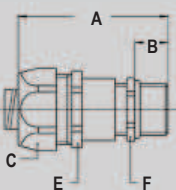

Gewinde NPT	UIG / UI NW (Zoll)	Klemm- bereich (mm)	Abmessungen in mm					Standard Verpackung	Artikel Nummer	Gewicht (Kg/100)
			A	B	C	E	F			
3/8" NPT	5/16"	4 - 6,8	60	15	26	24	17	25	814.709.7	9,2
3/8" NPT	3/8"	4 - 8	60	15	26	24	17	25	814.710.7	9,4
1/2" NPT	3/8"	6 - 9,8	57	13	26	24	22	25	814.712.7	13,3
1/2" NPT	1/2"	6 - 12	59	13	29	27	22	25	814.715.7	13,5
3/4" NPT	3/4"	13 - 18	68	13	35	33	30	25	814.721.7	22,6

**ANACONDA  
MULTIFLEX**

**VERSCHRAU-  
BUNGEN FÜR  
TYP UIG / UI  
IP 40**