



Raccord CEM mâle presse-étoupe ISO en laiton nickelé (kit de raccordement inclus)

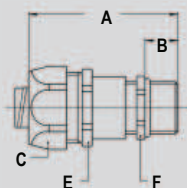


Filetage ISO	UI et UIG (Pouce)	Diamètre de serrage (mm)	Dimensions en mm					Condition. Standard	Référence Article	Poids (Kg/100)
			A	B	C	E	F			
M16 x 1,5	5/16"	4 - 6,8	57	12	26	24	18	10	812.615.7	7,4
M16 x 1,5	3/8"	4 - 8	57	12	26	24	18	10	812.616.7	9,4
M20 x 1,5	3/8"	6 - 9,8	57	12	26	24	22	10	812.617.7	11,1
M20 x 1,5	1/2"	6 - 12	59	12	29	27	22	10	812.620.7	11,5
M25 x 1,5	1/2"	10 - 13,9	62	12	29	27	27	5	812.622.7	13,5
M32 x 1,5	3/4"	13 - 18	70	15	35	33	34	5	812.628.7	22,6
M40 x 1,5	1"	18 - 22,8	83	15	45	43	43	2	812.635.7	38,0

Raccord mâle droit Pg en laiton nickelé (kit de raccordement inclus)

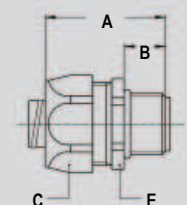


Filetage Pg	UI et UIG (Pouce)	Diam. intérieur Min. (mm)	Dimensions en mm					Condition. Standard	Référence Article	Poids (Kg/100)
			A	B	C	D	E			
Pg 9	5/16"	6,8	35	12	26	-	24	10	810.009.7	6,4
Pg 11	5/16"	6,8	35	12	26	-	24	10	810.012.7	7,2
Pg 9	3/8"	9,8	35	12	26	-	24	10	810.010.7	6,4
Pg 11	3/8"	9,8	35	12	26	-	24	10	810.011.7	7,2
Pg 13,5	3/8"	9,8	35	12	26	-	24	10	810.013.7	7,2
Pg 16	1/2"	13,9	37	13	29	-	27	10	810.016.7	8,1
Pg 21	3/4"	18,5	40	15	35	-	33	5	810.021.7	11,4
Pg 29	1"	22,8	46	15	45	-	43	5	810.029.7	27,6
Pg 36	1.1/4"	30,8	52	16	54	-	52	2	810.036.7	38,4
Pg 42	1.1/2"	36,8	56	18	63	-	60	2	810.042.7	52,8
Pg 48	2"	47,8	66	20	77	-	74	2	810.048.7	81,4

Raccord femelle droit Pg en laiton nickelé (kit de raccordement inclus)

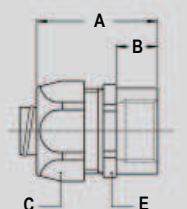

Filetage Pg	UI et UIG (Pouce)	Diam. intérieur Min. (mm)	Dimensions en mm					Condition. Standard	Référence Article	Poids (Kg/100)
			A	B	C	D	E			
Pg 11	5/16"	6,8	35	12	26	-	24	10	810.312.7	6,7
Pg 11	3/8"	9,8	35	12	26	-	24	10	810.311.7	6,9
Pg 13,5	5/16"	6,8	35	12	26	-	24	10	810.314.7	7,2
Pg 13,5	3/8"	9,8	35	12	26	-	24	10	810.313.7	7,4
Pg 16	1/2"	13,9	37	13	29	-	27	10	810.316.7	8,1
Pg 21	3/4"	18,5	40	15	35	-	33	5	810.321.7	12,3
Pg 29	1"	22,8	46	15	45	-	43	5	810.329.7	23,3
Pg 36	1.1/4"	30,8	52	16	54	-	52	2	810.336.7	33,1
Pg 42	1.1/2"	36,8	56	18	63	-	60	2	810.342.7	48,8
Pg 48	2"	47,8	66	20	77	-	74	2	810.348.7	84,2

Raccord mâle droit Pg tournant en laiton nickelé (kit de raccordement inclus)

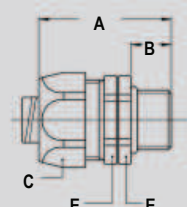

Filetage Pg	UI et UIG (Pouce)	Diam. intérieur Min. (mm)	Dimensions en mm					Condition. Standard	Référence Article	Poids (Kg/100)
			A	B	C	D	E			
Pg 9	5/16"	6,8	41	12	26	-	24	10	811.009.7	8,2
Pg 11	3/8"	9,8	41	12	26	-	24	10	811.011.7	8,4
Pg 16	1/2"	13,9	43	13	29	-	27	10	811.016.7	10,6
Pg 21	3/4"	18,5	48	15	35	-	33	5	811.021.7	16,6
Pg 29	1"	22,8	54	15	45	-	43	5	811.029.7	30,0

ANACONDA
MULTIFLEX

RACCORDS
POUR GAINES
UI ET UIG
IP 40