



**ISO gerade EMV Kabel-Schlauch-Verschraubung, Aussengewinde, Messing-vernickelt (einschl. Einschraubset).**

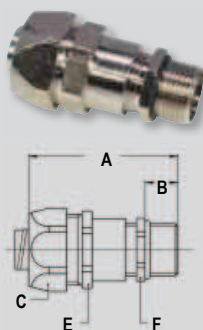


Gewinde	UIG / UI NW (Zoll)	Klemm- bereich (mm)	Abmessungen in mm					Standard Verpackung	Artikel Nummer	Gewicht (Kg/100)
			A	B	C	E	F			
M16 x 1,5	5/16"	4 - 6,8	57	12	26	24	18	10	812.615.7	7,4
M16 x 1,5	3/8"	4 - 8	57	12	26	24	18	10	812.616.7	9,4
M20 x 1,5	3/8"	6 - 9,8	57	12	26	24	22	10	812.617.7	11,1
M20 x 1,5	1/2"	6 - 12	59	12	29	27	22	10	812.620.7	11,5
M25 x 1,5	1/2"	10 - 13,9	62	12	29	27	27	5	812.622.7	13,5
M32 x 1,5	3/4"	13 - 18	70	15	35	33	34	5	812.628.7	22,6
M40 x 1,5	1"	18 - 22,8	83	15	45	43	43	2	812.635.7	38,0

**Pg gerade Verschraubung, Aussengewinde, Messing-vernickelt (einschl. Einschraubset).**

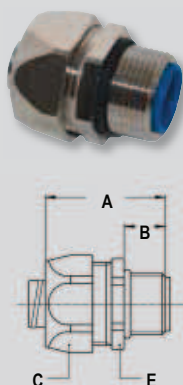


Gewinde	UIG / UI NW (Zoll)	Min. Innen Durchm. (mm)	Abmessungen in mm					Standard Verpackung	Artikel Nummer	Gewicht (Kg/100)
			A	B	C	D	E			
Pg 9	5/16"	6,8	35	12	26	-	24	10	810.009.7	6,4
Pg 11	5/16"	6,8	35	12	26	-	24	10	810.012.7	7,2
Pg 9	3/8"	9,8	35	12	26	-	24	10	810.010.7	6,4
Pg 11	3/8"	9,8	35	12	26	-	24	10	810.011.7	7,2
Pg 13,5	3/8"	9,8	35	12	26	-	24	10	810.013.7	7,2
Pg 16	1/2"	13,9	37	13	29	-	27	10	810.016.7	8,1
Pg 21	3/4"	18,5	40	15	35	-	33	5	810.021.7	11,4
Pg 29	1"	22,8	46	15	45	-	43	5	810.029.7	27,6
Pg 36	1.1/4"	30,8	52	16	54	-	52	2	810.036.7	38,4
Pg 42	1.1/2"	36,8	56	18	63	-	60	2	810.042.7	52,8
Pg 48	2"	47,8	66	20	77	-	74	2	810.048.7	81,4

**Pg gerade Verschraubung, Innengewinde, Messing-vernickelt (einschl. Einschraubset).**

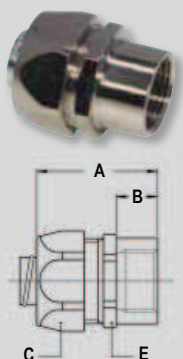

Gewinde	UIG / UI NW (Zoll)	Min. Innen Durchm. (mm)	Abmessungen in mm					Standard Verpackung	Artikel Nummer	Gewicht (Kg/100)
			A	B	C	D	E			
Pg 11	5/16"	6,8	35	12	26	-	24	10	810.312.7	6,7
Pg 11	3/8"	9,8	35	12	26	-	24	10	810.311.7	6,9
Pg 13,5	5/16"	6,8	35	12	26	-	24	10	810.314.7	7,2
Pg 13,5	3/8"	9,8	35	12	26	-	24	10	810.313.7	7,4
Pg 16	1/2"	13,9	37	13	29	-	27	10	810.316.7	8,1
Pg 21	3/4"	18,5	40	15	35	-	33	5	810.321.7	12,3
Pg 29	1"	22,8	46	15	45	-	43	5	810.329.7	23,3
Pg 36	1.1/4"	30,8	52	16	54	-	52	2	810.336.7	33,1
Pg 42	1.1/2"	36,8	56	18	63	-	60	2	810.342.7	48,8
Pg 48	2"	47,8	66	20	77	-	74	2	810.348.7	84,2

**Pg gerade Verschraubung, drehbare Ausführung, Aussengewinde, Messing-vernickelt (einschl. Einschraubset).**

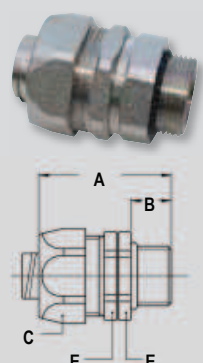

Gewinde	UIG / UI NW (Zoll)	Min. Innen Durchm. (mm)	Abmessungen in mm					Standard Verpackung	Artikel Nummer	Gewicht (Kg/100)
			A	B	C	D	E			
Pg 9	5/16"	6,8	41	12	26	-	24	10	811.009.7	8,2
Pg 11	3/8"	9,8	41	12	26	-	24	10	811.011.7	8,4
Pg 16	1/2"	13,9	43	13	29	-	27	10	811.016.7	10,6
Pg 21	3/4"	18,5	48	15	35	-	33	5	811.021.7	16,6
Pg 29	1"	22,8	54	15	45	-	43	5	811.029.7	30,0

ANACONDA  
MULTIFLEX

VERSCHRAU-  
BUNGEN FÜR  
TYP UIG / UI  
IP 40